


## LED Panel Series

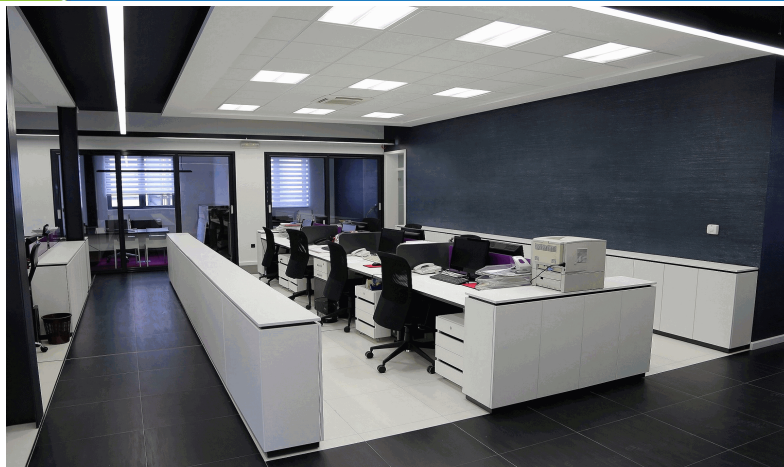

### VT-1422 RD

#### HIGHLIGHTS :

WATTS



22

EQ. WATTS



66

LUMINOUS



1700

BEAM ANGLE



120

Item No	: VT-1422 RD
SKU Code	: 4817
Watts	: 22
EQ Watts	: 66
Voltage	: 110-265V,50/60Hz
Lumen(lm)	: 1700
Color Temperature	: 3000K
Beam Angle	: 120
Commercial type	: ROUND
PF	: >0.9
LED Chip Type	: SMD
CRI	: >80
Energy rating label	: A
Certification	: CE,EMC,ROHS
IP Rating Protection Class	: IP20

Body type	: PKW
Dimmable	: No
Life Time	: >20,000 Hours
Operation Temperature	: -25 ~50°C
EAN code	: 3800230622853
Unit size	: D:235x35mm
Cutting size	: D:190mm
Packing details	: 20
Unit cbm	: 0.003596

#### PRODUCT FEATURES

- Compare with incandescent, it can save over 80% electric cost
- Contemporary & Elegant Design
- Higher Light Transmission Rate
- No flickering, No U.V Radiation
- No Lead or Mercury content hence Environment friendly
- Suitable for office and genral lighting (Conference Room, Showroom, lobby, cabin, kitchen etc.)
- High quality power driver
- Instant light 100% O s
- Temp -20 to + 45°C

CLICK HERE  
FOR OTHER RELATED CERTIFICATES

