



### PERFECT cable gland

#### Configuration

Dome nut	Polyamide PA6 V-2
Sealing ring	Polychloroprene-Nitrile rubber CR/NBR
Gland body	Polyamide PA6 V-2
Connecting thread	metric, as per EN 60423

#### Properties


	<ul style="list-style-type: none"> <li>with spiral top,</li> <li>for movable flexible cables,</li> <li>integrated anchorage</li> <li>wide sealing and clamping range</li> <li>easy-to-install</li> </ul>
Temperature range	-20°C +100°C
Protection grade	IP68 5bar
Test standard	EN 50262 UL 514B
VDE licence	40020902
UL / CSA-File	E140310
ESTI licence	09.0418
Comment	details about tests - see annex

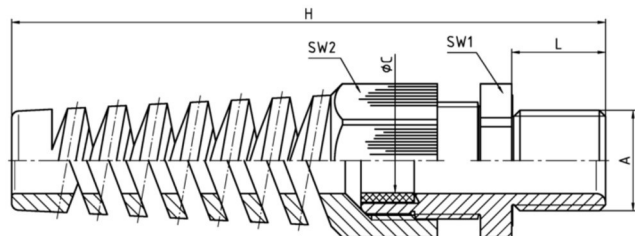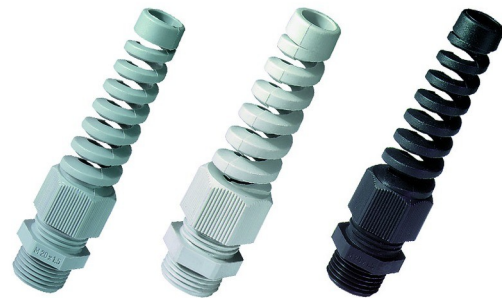

#### Features


 RAL 9005

Connecting thread standard length

A	ØC	L	SW1	SW2	H		Part No.
	mm	mm	mm	mm	mm	Piece	
M12x1,5	3 - 6,5	8	15	15	63,5	100	50007M12BSSW
M16x1,5	5 - 10	15	22	22	94,5	100	50011M16BSSW
M20x1,5	6 - 12	11	24	24	101,5	50	50013M20BSSW
M20x1,5	10 - 14	15	27	27	116	50	50016M20BSSW
M25x1,5	13 - 18	15	33	33	132,5	50	50021M25BSSW

 RAL 7035


Connecting thread standard length

A	ØC	L	SW1	SW2	H		Part No.
	mm	mm	mm	mm	mm	Piece	
M12x1,5	3 - 6,5	8	15	15	63,5	100	50007M12BS7035
M16x1,5	5 - 10	15	22	22	94,5	100	50011M16BS7035
M20x1,5	6 - 12	11	24	24	101,5	50	50013M20BS7035
M20x1,5	10 - 14	15	27	27	116	50	50016M20BS7035
M25x1,5	13 - 18	15	33	33	132,5	50	50021M25BS7035



RAL 7001

Connecting thread standard length

A	ØC	L	SW1	SW2	H		Part No.
	mm	mm	mm	mm	mm	Piece	
M12x1,5	3 - 6,5	8	15	15	63,5	100	50007M12PABS
M16x1,5	5 - 10	15	22	22	94,5	100	50011M16PABS
M20x1,5	6 - 12	11	24	24	101,5	50	50013M20PABS
M20x1,5	10 - 14	15	27	27	116	50	50016M20PABS
M25x1,5	13 - 18	15	33	33	132,5	50	50021M25PABS