

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0050375103

Status:


Active

Overview:

Mini-SPOX Wire-to-Board Connector System

Description:

2.50mm Pitch Mini-SPOX Wire-to-Board Crimp Housing, without Friction Lock, 10 Circuits, Natural

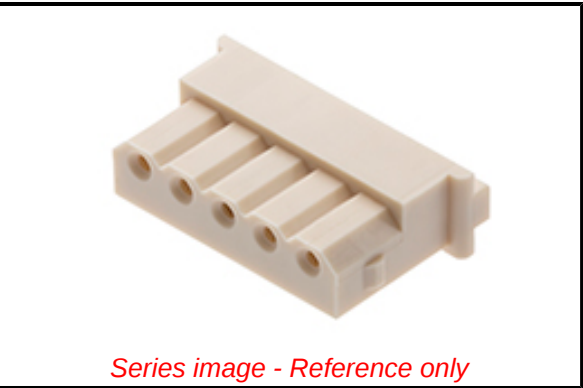

Series image - Reference only

Documents:

3D Model

Drawing (PDF)

Product Specification PS-5264-001-001 (PDF)

Packaging Specification SPK-5264-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
UL	E29179
General	
Product Family	Crimp Housings
Series	5264
Application	Signal, Wire-to-Board
Overview	Mini-SPOX Wire-to-Board Connector System
Product Name	Mini-SPOX
UPC	800753749535
Physical	
Circuits (maximum)	10
Color - Resin	Natural
Flammability	94V-0
Gender	Receptacle
Glow-Wire Capable	No
Lock to Mating Part	No
Material - Resin	Nylon
Net Weight	541.800/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.50mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C
Material Info	
Engineering Number	5264-10
Reference - Drawing Numbers	
Packaging Specification	SPK-5264-001-001
Product Specification	PS-5264-001-001
Sales Drawing	SD-5264-N-001, SD-5264-N-002

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per	
-ED/88/2018 (15	
January 2019)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

5264 Series

Mates With

Mini-SPOX Vertical Header 5267 . Mini-SPOX Right-Angle Header 5268

Use With

Mini-SPOX Receptacle Terminal 5263

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION