

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0511100460](#)  
**Status:** **Active**  
**Overview:** [Milli-Grid Connector System](#)  
**Description:** 2.00mm Pitch, Milli-Grid Receptacle Housing, 4 Circuits, without Center Polarization Key, with Locking Ramp, Lead-Free

**Documents:**

[3D Model](#) [Packaging Specification PK-51110-300-001 \(PDF\)](#)  
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Product Specification PS-51110-001-001 \(PDF\)](#)

**Agency Certification**

CSA LR19980  
 UL E29179

**Application tooling part link**

Application Tooling Part Link 63824-2800

**General**

Product Family Crimp Housings  
 Series [51110](#)  
 Application Signal, Wire-to-Board  
 Brochure Order No 987650-1991  
 Comments Applicable Wire Ranges: 24-30 AWG (series [50394](#) terminal) and 22-28 AWG (series [87396](#) terminal)  
 Applicable Wire Ranges: 24-30 AWG (series [50394](#) terminal) and 22-28 AWG (series [87396](#) terminal)  
 Overview [Milli-Grid Connector System](#)  
 Product Name Milli-Grid  
 UPC 800755558142

**Physical**

Circuits (maximum) 4  
 Color - Resin Black  
 Flammability 94V-0  
 Gender Receptacle  
 Glow-Wire Capable No  
 Keying to Mating Part None  
 Lock to Mating Part Yes  
 Material - Resin Polyester  
 Net Weight 0.080/g  
 Number of Rows 2  
 Packaging Type Bag  
 Panel Mount No  
 Pitch - Mating Interface 2.00mm  
 Pitch - Termination Interface 2.00mm  
 Polarized to Mating Part Yes  
 Stackable No  
 Temperature Range - Operating -40° to +105°C


**Solder Process Data**

Lead-free Process Capability N/A

**Material Info**

**Reference - Drawing Numbers**

Packaging Specification PK-51110-300-001  
 Product Specification PS-51110-001-001

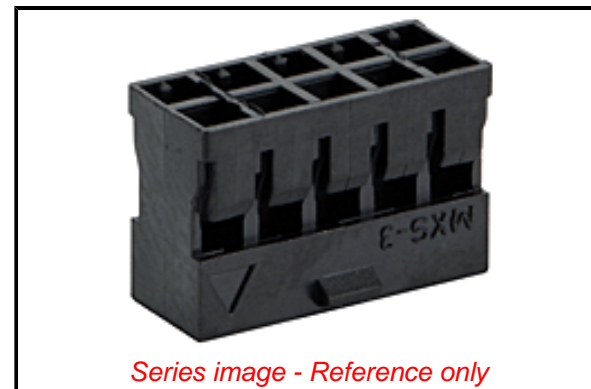

Series image - Reference only

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per  
 -ED/88/2018 (15  
 January 2019)

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[51110 Series](#)

**Mates With**

Milli-Grid Headers [87758](#) , [87759](#) , [87760](#) , [87831](#) , [87832](#) <br>Milli-Grid BMI Header [151013](#) <br>Milli-Grid Low-Halogen Headers [151117](#) , [151118](#) , [151119](#) , [151120](#)

**Use With**

[50394](#) , [87396](#) Crimp Terminals

**Application Tooling | FAQ**

*Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.*

**Global**

**Description**

**Product #**

Extractor Tool for Milli-Grid 2.0 Housings [638242800](#)

This document was generated on 08/05/2019

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**