

FEATURES

- Grade 8 steel, bright zinc plated
- M3 metric threading
- Self-locking due to glass filled nylon insert
- Remain secure despite conditions of severe vibration

RS PRO, M3, Bright Zinc Plated Steel Nylon Insert Lock Nut

RS Stock No.: 524-281



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

Brought to you by RS Pro, this nylon insert locking nut is made of a bright zinc plated steel and offers excellent corrosion resistance. This lock nut is self-locking due to a glass filled nylon insert and features M3 metric internal threading to couple with a threaded rod. The nut is designed to remain secure despite conditions of severe vibration..

General Specifications

Thread Size	M3
Type	Nylon Insert
Material	Steel
Finish	Bright Zinc Plated
Grade	8
Applications	Locking nuts work to secure bolted joints by adding friction to the thread of the bolt


Mechanical Specifications

Width	6.01mm
Specification	DIN 982
Thickness	4.02mm To 4.5mm
Thread Pitch	0.5
Width Across Corners	6.01mm
Width Across Flats	5.32 To 5.5mm
Wrenching Height	1.72mm

Approvals

Compliance/Certifications

RoHS

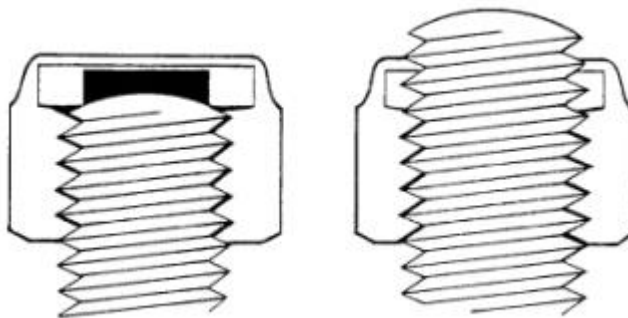

RS Part No.	Thread Size
524281	M3
524304	M4
524310	M5
524326	M6
530393	M8
530400	M10
530416	M12