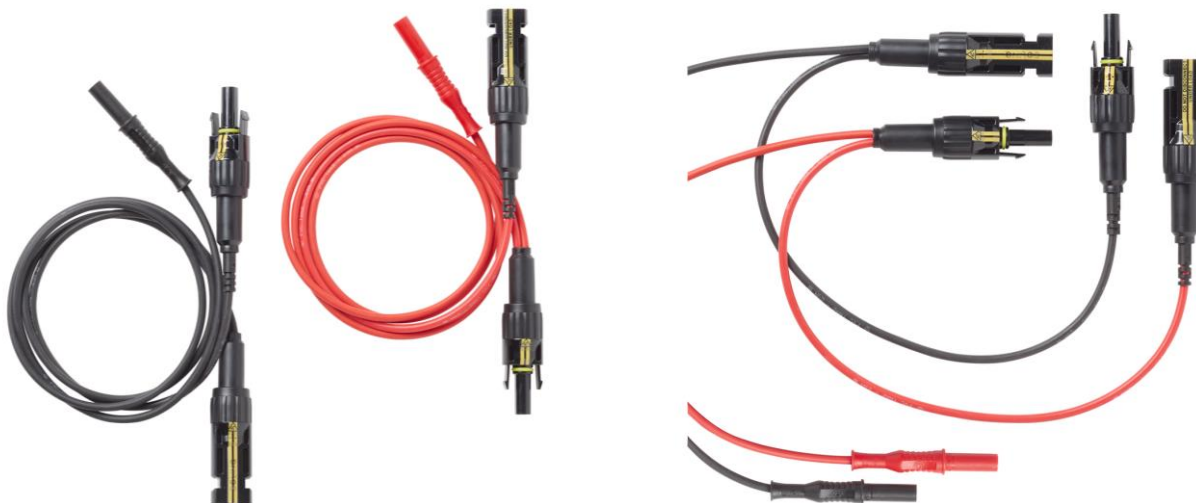


Model PVLEAD3
MC4 Solar Clamp Test Lead Set**Features**

- Set of black and red MC4 Solar Power Clamp Test Leads
- The black test lead is a MC4 (male) breakout to 12-inch MC4 (female) and 36-inch 4mm sheathed banana plug test lead
- The red test lead is a MC4 (female) breakout to 12-inch MC4 (male) and 36-inch 4mm sheathed banana plug test lead
- Designed for use with Solar Clamp Meters that accept 4mm sheathed banana plugs
- Creates connection between the Solar Panel and Inverter for measuring with a Clamp Meter
- Ensures safe DC power measurements on Photovoltaic (PV) modules and systems
- Allows user to monitor solar PV circuits during operation for troubleshooting and maintenance of PV systems
- Nickel plated contacts

Ratings

Voltage: Complies to IEC / EN 61010-031
CAT III 1000V / CAT IV 600V
Do Not Disconnect Under Load

Current: 20A

Temperature Range: +5°C to +40°C (+41°F to +104°F)

Ordering Information

Model: PVLEAD3
MC4 SOLAR POWER CLAMP SET



USA: Sales: 800-490-2361
Technical Support: technicalsupport@pomonatest.com
Europe: 31-(0) 40 2675 150 **International:** 425-446-5500
Where to Buy: www.pomonaelectronics.com

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ±.005" (.127 mm). All specifications are to the latest revisions. Specifications are subject to change without notice. Registered trademarks are the property of their respective companies.