


FEATURES

- Ideal for precision work with soft wire
- Precision ground 3mm steel jaws
- Ribbed soft plastic grips and lightweight return spring
- Integral stop prevents handles opening too far

RS PRO 140mm Steel Flat Nose Pliers With 30mm Jaw Length

RS Stock No.: 606-529

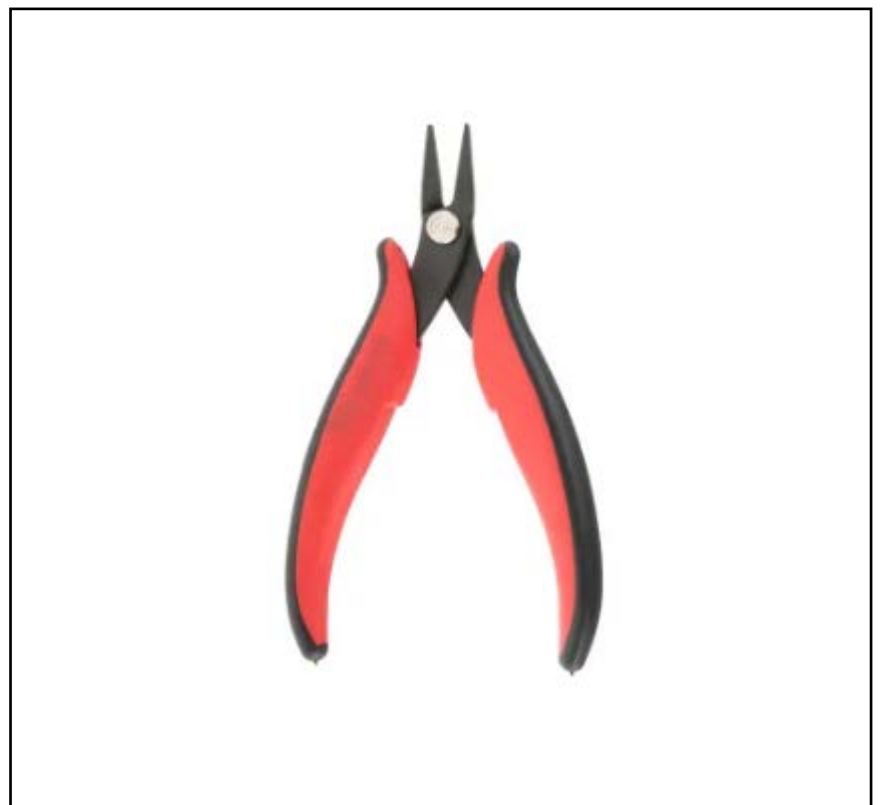

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

From RS PRO, these high-quality long nose pliers are suitable for professionals and enthusiasts alike. With rounded external edges, these smooth pointed pliers are suitable for the handling of components in high-density areas without causing damage.

General Specifications

Plier Type	Flat Nose Pliers
Tip Style	Straight
Material	Steel
Applications	Electrical Work, Jewellery Making

Mechanical Specifications

Cutting Capacity	3mm
Jaw Length	30mm
Overall Length	140mm
Weight	78g



<p>All dimensions are in mm</p>	<p>FLAT NOSE PLIER</p>	<p>P10</p> <ul style="list-style-type: none"> ● Precision nose plier with serrated jaws ● Jaw width 3mm ● Length 140mm
<p>All dimensions are in mm</p>	<p>LONG NEEDLE NOSE PLIER</p>	<p>P11</p> <ul style="list-style-type: none"> ● Long-needle nose plier with serrated jaws ● Tapered jaw to 1.2mm width ● Length 152mm
<p>All dimensions are in mm</p>	<p>FLUSH CUTTER</p>	<p>P13</p> <ul style="list-style-type: none"> ● Max wire ϕ 16 AWG/.051" (1.3mm) soft wire ● Cutting angle 21° ● Length 132mm ● Safety clip available. Add "-A" to Part No.
<p>All dimensions are in mm</p>	<p>LIGHTWEIGHT FLUSH CUTTER</p>	<p>P13-LW</p> <ul style="list-style-type: none"> ● Max wire ϕ 16 AWG/.051" (1.3mm) soft wire ● Cutting angle 21° ● Lightweight 1.6oz (45g) ● Length 125mm ● Safety clip available. Add "-A" to Part No.
<p>All dimensions are in mm</p>	<p>ANGLED FLUSH CUTTER</p>	<p>P14</p> <ul style="list-style-type: none"> ● Max wire ϕ 16 AWG/.051" (1.3mm) soft wire ● Cutting angle 21° ● Length 130mm ● Safety clip available. Add "-A" to Part No.
<p>All dimensions are in mm</p>	<p>FLUSH CUTTER</p>	<p>P15</p> <ul style="list-style-type: none"> ● Max wire ϕ 16AWG/.051" (1.3mm) ● Cutting angle 48° ● Length 130mm
<p>All dimensions are in mm</p>	<p>ANGLED HEAD CUTTER</p>	<p>P17</p> <ul style="list-style-type: none"> ● Max wire ϕ 18 AWG/.040" (1.0mm) ● Cutting angle 30° ● Length 140mm
<p>All dimensions are in mm</p>	<p>WIRE STRIPPER</p>	<p>P21</p> <ul style="list-style-type: none"> ● Max wire ϕ 28-24 AWG/.012"-.020" (0.3-0.5mm) ● Length 132mm
<p>All dimensions are in mm</p>	<p>LONG FLAT NOSE PLIER</p>	<p>P24</p> <ul style="list-style-type: none"> ● Long flat nose plier with serrated jaws. ● Jaw width 3mm ● Length 152mm