


Deep groove ball bearings, single row, low-friction seal on both sides



Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
25	37	7	4,36	2,6	0,125	38000	19000	0,022	61805-2RZ

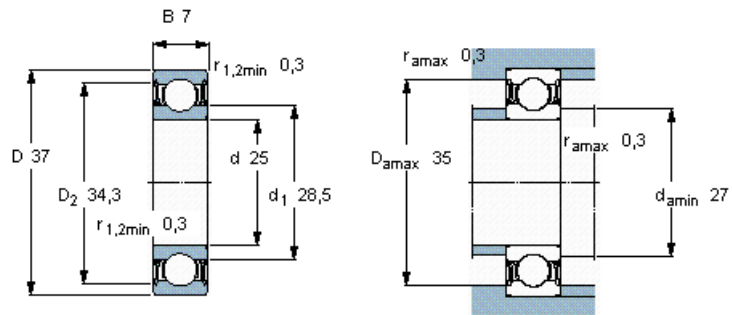

Calculation factors

k_r 0,015

f_0 14