

BRIGHT

- White LED provides 13 lumens in high mode
- Illuminate objects up to 18 meters away



HANDS-FREE

- After activated, no need to hold down switch to use light
- Leaves both hands free



MODERN

- Slim profile and smooth surface
- No corners to snag on objects



HANDY

- Key ring attachment included
- Large, easy to find switch



632628

EMEA Region

Sleek, compact and lightweight, The Energizer® Hi-Tech LED Keyring is an ideal keychain light. The three modes - high, low and flash - remain activated after pressing the switch, leaving both hands free to deal with keys or dropped objects. It has a durable cast metal body and is impact resistant. The white LED provides 13 lumens – more light than some larger flashlights – in a size that fits in your purse or pocket with ease. And if you forget to turn it off or it turns on accidentally, it features an auto shut-off to maintain battery life.




Before Using Your Flashlight:
Please read all instructions and cautionary markings on the package and light

EMEA Region

Product Detail:

- Designation:** Energizer Hi-Tech LED Keyring
- SAP:** 632628
- Colour:** Brushed Chrome
- Power Source:** Two CR2016 Lithium Coin Cells
- IEC:** CR2016
- Lamp:** 1 White LED
- Lamp Life (hr):** Lifetime
- Lamp Output (lumens):** High - 13
- Beam Distance (m):** 18
- Peak Beam Intensity (cd):** 82
- Run Time (h:mm):** 5:30 continuous operation in High mode
- Typical Weight:** 29.3 grams with batteries
- Dimensions (mm):** 10 x 50 x 24

Performance:

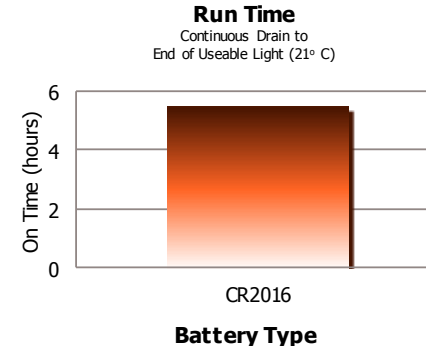

Tested according to ANSI/NEMA FL 1 Standards.

Important Notice

This datasheet contains information specific to products manufactured at the time of its publication
Contents herein do not constitute a claim or warranty
©Energizer / All Rights Reserved