


64255 20 W 8 V

Halogen lamps with reflector MR11



Product features

- Xenon instead of krypton as the filler gas (XENOPHOT HLX versions)
- Luminous flux up to 10 % higher with same power consumption (XENOPHOT HLX versions)

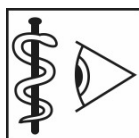


Technical data

Electrical data

Nominal voltage	8 V
Nominal wattage	20 W

Dimensions & weight

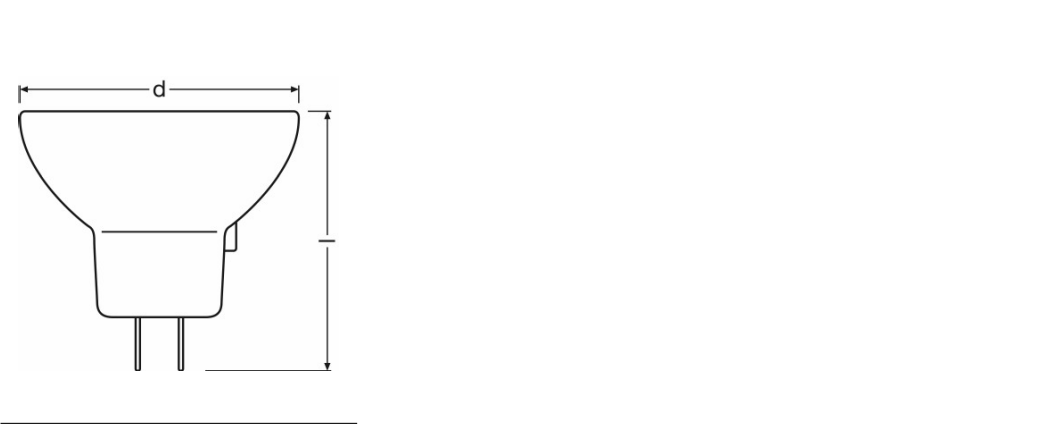

Product line drawing

Diameter	35.0 mm
Length	32.0 mm

Lifespan

Lifespan	50 h
----------	------

Additional product data

Base (standard designation)	G4
Coating	Dichroic
Picto Medicine	Yes

Certificates & standards

EEL – Energy Label	B
--------------------	---

Country specific categorizations


Order reference	64255
-----------------	-------

Country specific information

Product datasheet

Product code	METEL code	SEG-No.	STK-Number	UK Org
4050300006833	OSRH64255	-	-	-

Product datasheet

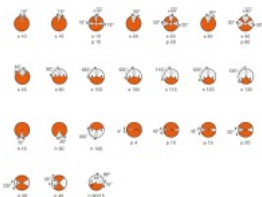

Burning position

Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (height x width x length)	Volume	Gross weight
4050300006833	64255 20 W 8 V	Folding carton box 1	34 mm x 34 mm x 50 mm	0.06 dm ³	15.40 g
4050300664668	64255 20 W 8 V	Shipping carton box 20	86 mm x 131 mm x 191 mm	2.15 dm ³	382.50 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

References / Links

For further technical information please refer to the following OSRAM brochure:
“Technology and applications, Low-voltage tungsten-halogen lamps”
“Halogen lamps, low and medium voltage for entertainment, technical and medical applications” cross reference list

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.