

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0643183011](#)
Status: **Active**
Overview: CMC and CMX Sealed, Hybrid, Modular Connectors
Description: .635mm, 1.50mm, 2.80mm, Power CMC Connector, 28 Circuits, Right Wire Output, Black Coding, Mat Sealed

Documents:

3D Model	Application Specification AS-64318-002-SP-001 (PDF)
Drawing (PDF)	Application Specification AS-98420-001-001 (PDF)
3D Model (PDF)	Application Specification AS-98420-001-CH-001 (PDF)
Product Specification PS-64321-001-001 (PDF)	Application Specification AS-98420-001-FR-001 (PDF)
Application Specification AS-64318-002-001 (PDF)	Application Specification AS-98420-001-SP-001 (PDF)
Application Specification AS-64318-002-CH-001 (PDF)	Datasheet (PDF)
Application Specification AS-64318-002-FR-001 (PDF)	RoHS Certificate of Compliance (PDF)

Application tooling part link

Application Tooling Part Link 63812-1100
 Application Tooling Part Link 63824-1200

General

Product Family Crimp Housings
 Series [64318](#)
 Application Automotive, Power, Wire-to-Board
 Comments * Current tested on a fully loaded connector, current for temperature increase of 40°C. Current max = 21.0A for 2.80mm Terminal (5.00mm² wire), 12.0A for 1.50mm Terminal (2.00mm² wire), 2.5A for 0.635mm Terminal(0.75mm² wire) *


[More Detailed Tech Information](#)

Overview

Product Name [CMC and CMX Sealed, Hybrid, Modular Connectors](#)
 UPC CMC 883906135133

Physical

Circuits (maximum) 28
 Circuits Detail 5x 2.8mm, 5 x 1.5mm, 18 x 0.635mm terminals
 Color - Resin Black
 Gender Receptacle
 Glow-Wire Capable No
 Keying to Mating Part Yes
 Lock to Mating Part Yes
 Material - Resin Polyester
 Net Weight 35.290/g
 Number of Rows 3
 Packaging Type Carton
 Panel Mount No
 Pitch - Mating Interface 2.54mm, 3.50mm, 6.75mm
 Polarized to Mating Part Yes
 Stackable No

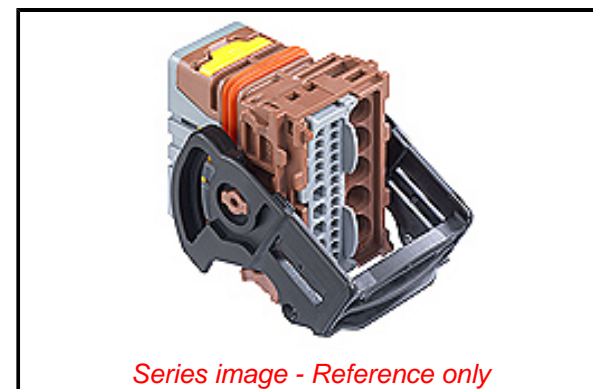

Series image - Reference only

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - D(2021)10043-DC (17 Jan 2022)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Compliant

Not Contained

Search Parts in this Series

[64318 Series](#)

Mates With

CMC Header [47745](#) - please contact Molex for details

Use With

CMC CP Female Terminal [64322](#) (0.635mm), [64323](#) (1.50mm), [64324](#) (2.80mm) . CMC Wire Cap [643201301](#) . Sealing Plugs [643251010](#) , [643251023](#) , [643251091](#)

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description

Product #

Continuity Test Pen Assembly [638121100](#)

Temperature Range - Operating -40° to +125°C

Electrical

Current - Maximum per Contact 12.0A, 2.5A, 21.0A

Solder Process Data

Lead-freeProcess Capability N/A

Material Info

Reference - Drawing Numbers

Application Specification AS-64318-002-001, AS-64318-002-CH-001,
AS-64318-002-FR-001, AS-64318-002-SP-001,
AS-98420-001-001, AS-98420-001-CH-001,
AS-98420-001-FR-001, AS-98420-001-SP-001
Product Specification PS-64321-001-001
Sales Drawing SD-64318-001-001

Unlocking Tool 638241200
for CMC and
CMX Receptacle
Connector

This document was generated on 04/14/2022

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION