

FEATURES

- Made using PVC in black
- It is strong and durable
- Provide protection to the cables passing through
- They are designed for holes 10mm wide and panels 1.7mm thick

RS PRO Black PVC 10mm Round Cable Grommet for Maximum of 6.4mm Cable Dia.

RS Stock No.: 666-4590



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

A selection of 8 different sized standard grommets (type 1) and 2 different sized easy fit grommets (type 2). Suitable refills for PVC Black Grommet Kit, Stock no. 666-4584. Supplied in bags of 100.

[666-4593](#) - 8.5 mm
[666-4596](#) - 10.2 mm
[666-4590](#) - 13.3 mm
[666-4600](#) - 15.5mm
[666-4603](#) - 19.5 mm
[666-4607](#) - 23.7 mm
[666-4613](#) - 23.9 mm
[666-4616](#) - 29.9 mm
[666-4622](#) - 30 mm
[666-4619](#) - 38.1 mm

General Specifications

Grommet Type	Round
Material	PVC
Colour	Black

Mechanical Specifications

Maximum Panel Thickness	1.7mm
Panel Hole Diameter	10mm
Maximum Cable Diameter	6.4mm
Minimum Panel Thickness	1.7mm
Cable Diameter Range	0~6.4mm


Approvals

Standards Met	ANSI/ESD S20.20:2014 and BS EN 61340-5-1:2007
----------------------	---





Dimensions						
Type	A (mm)	B (mm)	C (mm)	D (mm)	E (mm)	Stock no.
1	8.5	6.0	3.0	4.7	1.7	666-4593
1	10.2	7.2	5.0	4.4	1.7	666-4596
1	13.3	10.0	6.4	6.3	1.7	666-4590
1	15.5	11.0	7.8	9.0	3.0	666-4600
1	19.5	13.9	10.5	6.4	3.4	666-4603
1	23.7	20.1	15.5	6.1	1.7	666-4607
1	29.9	25.1	18.9	7.2	1.5	666-4616
1	38.1	31.7	25.0	7.8	1.5	666-4619

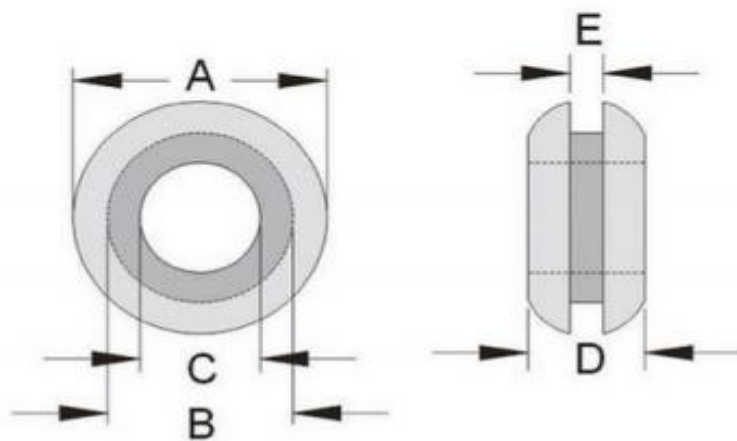

Dimension – mm