

Data Sheet

Universal Plug NG with screwed strain relief 15A

Art. Nr. 67762015 (BP)

Art. Nr. 67772015 (SP)

24.06.2019

Voltage range:	12 - 24 V DC
Current load:	max. 15 A
Connection:	screw terminals
tightening torque of the terminal screws:	25 – 35 cNm
strain relief screws:	25 – 35 cNm
Cable:	max. 2.5 mm ² , max. 7mm total Ø
Temperature range:	-25° C bis +85° C
Mating cycles:	up to 5000

Material:



Housing:	Polycarbonate
Temperature load:	Max. 135 °C
Connection spring:	Cu Fe2 P
Surface:	shiny pickled
Contact spring:	Cu Zn 37 F45
Surface:	gal. Ni 5
Plug pin:	Cu Zn 40 Pb 2
Surface:	gal. Ni 5

**Universal Plug NG
 with screwed strain relief 15A**

Art. Nr. 67762015 (BP)

Art. Nr. 67772015 (SP)

24.06.2019

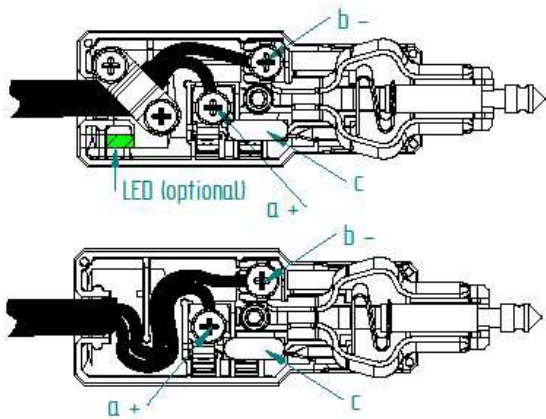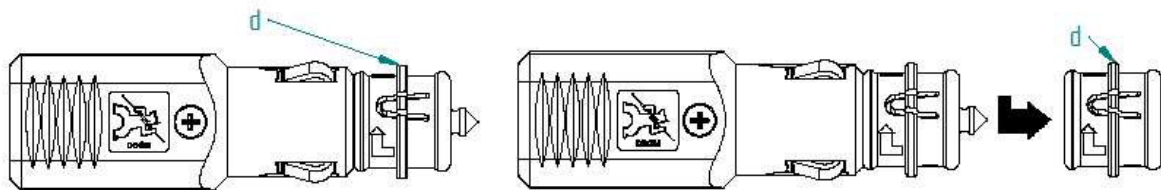

I	Pmax [W]	
	@ 12V	@ 24V
15 A	180	360