




Save as PDF



**Peli protector cases - Waterproof peli cases - 1620 case**

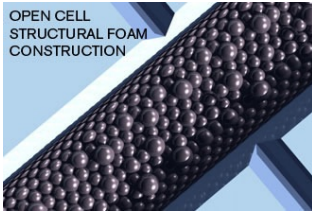

Interior dimensions:  
54.3 x 41.4 x 31.9 cm (21" x 16" x 13")

**Watertight, crushproof, and dust proof**

- Easy-open, double-step latches
- Open cell core with solid wall design - strong, light weight
- O-ring seal
- Automatic Pressure Equalization Valve
- Fold down handles
- Stainless steel hardware and padlock protectors
- 4 layer Pick 'N' Pluck™ foam with convoluted lid foam
- Personalised nameplate service available
- Unconditionally Guaranteed

**Retractable extension handle**

**Strong polyurethane wheels with stainless steel bearings**



Black

**Peli protector cases - Waterproof peli cases - 1620 case SPECIFICATIONS**

Exterior Dimensions (L x W x D)		Interior Dimensions (L x W x D)	
63 x 49.2 x 35.2 cm (25" x 19" x 14")		54.3 x 41.4 x 31.9 cm (21" x 16" x 13")	
Lid Depth	Bottom Depth	Total Depth	
5.2 cm (2")	26.7 cm (10.50")	31.9 cm 12.56")	
Lid Depth	Bottom Depth	Total Depth	
5.2 cm (2.06")	26.7 cm (10.50")	31.9 cm 12.56")	
Weight w/Foam	Weight w/o Foam	Buoyancy Max.	
11.8 kg. (26.01 lbs)	11.1kg (24.47 lbs.)	68 kg (149.91 lbs. )	
Range Temperature	No. of Wheels	Retractable Handle	
-40 / 99° C (-40 / 210° F)	2	Yes	

Personalized Nameplate Available

**1620EU Case Certificates**

- IP67(1 meter submersion for 30 minutes)
- MIL C-4150J
- Def Stan 81-41/STANAG 4280

**Materials**

Body	Latch	Lid O-Ring	Pins
Polypropylene	ABS	PolymerStainless Steel	
Foam	Purge Body	Purge Vent	Purge O-Ring
1.3 lb Polyurethane	ABS	3 Micron Hydrophobic Non-Woven PET	70 Shore Nitrile

**Configuration**

Cat. #	Description
1620EU	Peli protector cases - Waterproof peli cases - 1620 case

**Peli protector cases - Waterproof peli cases - 1620 case Accessories**

No accessories are currently available for this product