

► **Additional 15 mm longer version:**  
greater stability, improved cutting performance


- > Precision ground cutting edges without bevel for accurate flush cutting through the finest of wires e.g. in electronics and precision engineering
- > Precisely shaped tips also cut adjacent wires as from  $\varnothing 0.2$  mm
- > With opening spring and opening limiter for convenient, ergonomic and fast working due to automatic opening and user-friendly handle width
- > Extremely smooth movement for minimum operator fatigue due to joint with stainless steel rivet

**78 03 140 / 78 03 140 ESD**

Durable and stainless, made from INOX surgical steel, cutting edges hardened to 54 HRC

**78 61 140 / 78 61 140 ESD**

Heavy duty, made from burnished special tool steel, cutting edges additionally induction hardened to 64 HRC

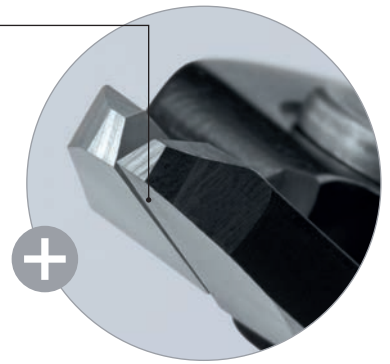

Shear cut with controlled micro cutting edge misalignment for the most precise cutting of even the thinnest of wires and for a long service life

78 03 140

Product video



78 61 140 ESD



140 mm length: stronger and extremely versatile



For flush cutting, e.g. to shorten cable ties

Article No.	EAN	↔ mm		Pliers	Head	Handles	⊙ mm	◐ mm	⚖ g
78 03 140	081647	140	▶▶		polished	with multi-component grips	0.2 - 2.1	1.2	95
78 03 140 ESD	081661	140	▶▶		polished	with multi-component grips	0.2 - 2.1	1.2	95
78 61 140	081685	140	▶▶	burnished		with multi-component grips	0.2 - 2.1	1.4	95
78 61 140 ESD	081708	140	▶▶	burnished		with multi-component grips	0.2 - 2.1	1.4	95