

# ARCA 806030W No MP

**FIBOX**  
Enclosing innovations



Sample image

**Order symbol :** ARCA 806030W No MP

**Product nr :** 8120139N

UL Code : UL508A

**Description :** Cabinet, PC




**Remarks :** Grey cover with window, 2-point locking, hinges on the long side

**EAN :** 6418074094049

**El. number :**

- Denmark : 8212054260

**Including :** Cabinet base. door with PUR gasket. 3mm double bit lock(s) with key. S versions with swinghandle 2-point locking system. Door guide included.

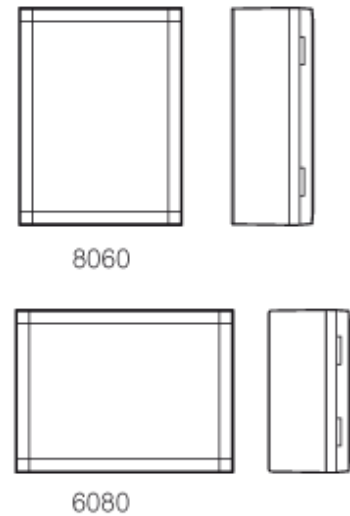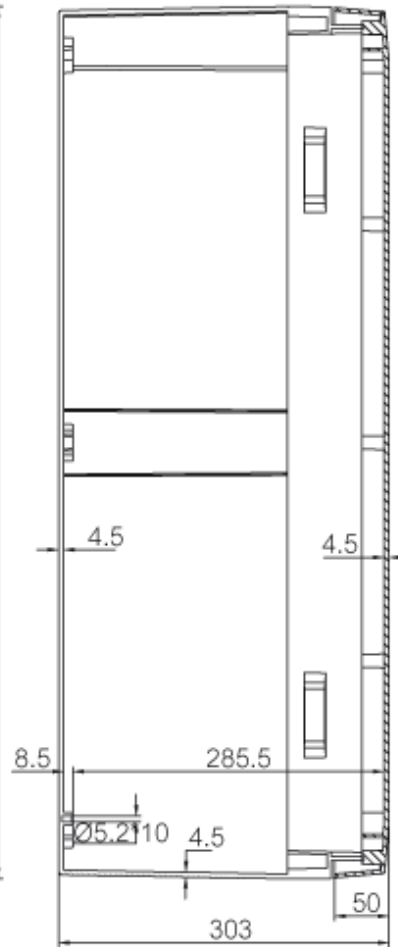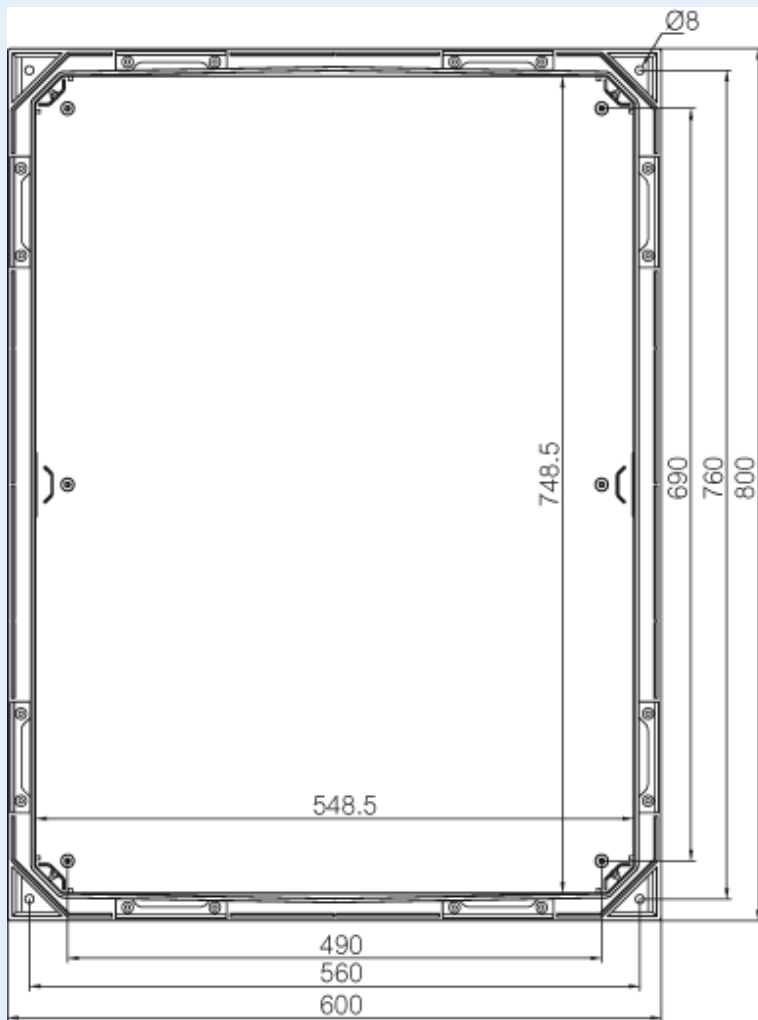

Dimensions :	Height	Width	Depth
mm :	800	600	300
inch :	31.5	23.62	11.81

#### Materials :

Material :	Polycarbonate
Base colour :	RAL_7035
Cover colour :	Clear transparent
Gasket material :	Polyurethane

#### Temperatures :

Temperature °C (continuous) :	-40 ... 80
Temperature °F (continuous) :	-40 ... 175

#### Accessories :

RCS ARCA 8060	Rain canopy set for size 8060
PMK ARCA 60	PoleMounting kit, for pole $\varnothing$ 100-300mm (585 x 385 x 35)
IDS ARCA 8060	Inner door set (785 x 585 x 35)
DSP ARCA RM	Door stopper ARCA, right, midsize 5070-8060
DRS ARCA 806030	DIN rail frame set (785 x 585 x 35)
MPS ARCA 8060	Mounting plate (730x530x2 mm)
DSP ARCA LM	Door stopper ARCA, left, midsize 5070-8060
MPMP ARCA 8060	Mounting plate multiperforated (730x530x2 mm - $\varnothing$ 3.6 mm)
MPP ARCA 8060	Mounting plate perforated (730x530x2 mm - 26x11 mm)
MPX ARCA 8060	Mounting plate (730x530 mm) (730 x 530 x 8)

#### Ratings :

Ingress protection (EN 60529):	IP65;
Impact Resistance (EN 62262):	IK08;
electrical_insulation :	Totally insulated

Halogen free (DIN/VDE 0472, Part 815) :	Yes
UV resistance :	UL 746C
Flammability Rating :	UL 94 5VA
Glow Wire Test (IEC 695-2-1) °C :	960C

**Certificates :**

Certificate FI 40467