

# ARCA 507030W No MP



Sample image

**Order symbol :** ARCA 507030W No MP

**Product nr :** 8120151N

UL Code : UL508A

**Description :** Cabinet, PC


**Remarks :** Grey cover with window, 2-point locking, hinges on the short side

**EAN :** 6418074094254

**El. number :**

- Denmark : 8212054189

**Including :** Cabinet base. door with PUR gasket. 3mm double bit lock(s) with key. S versions with swinghandle 2-point locking system. Door guide included.

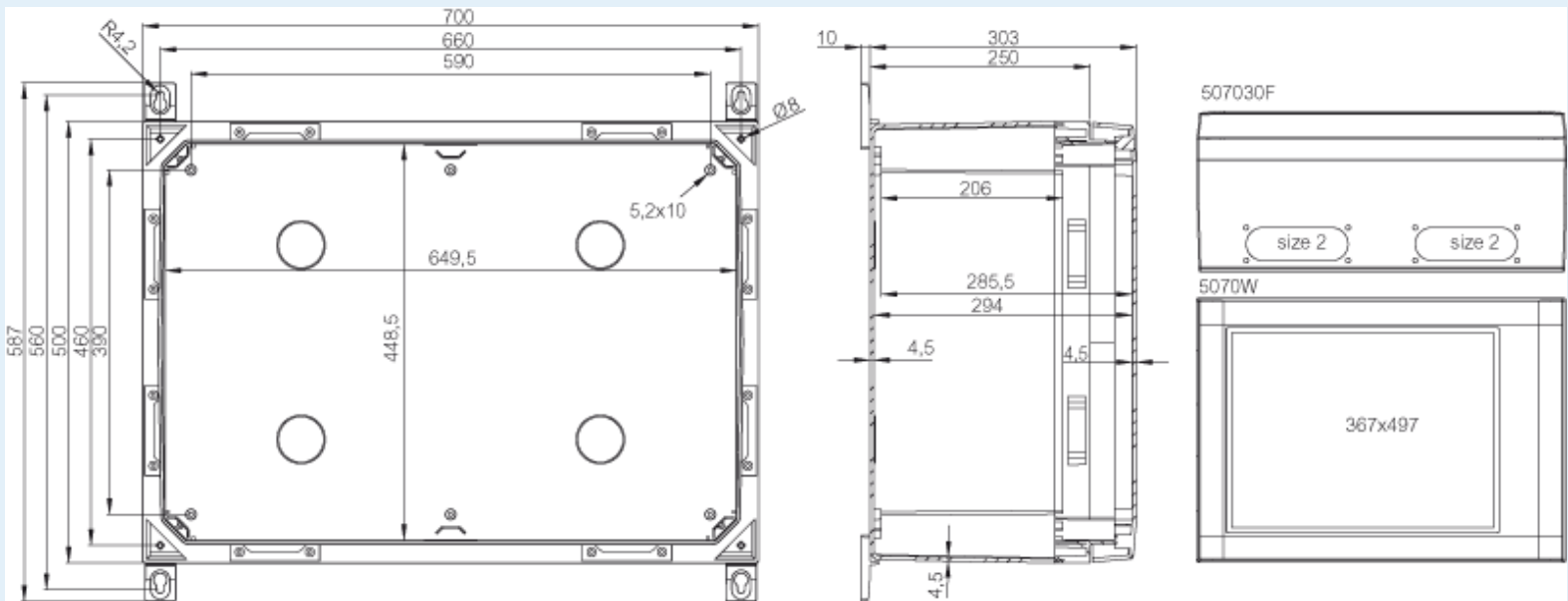

Dimensions :	Height	Width	Depth
mm :	500	700	300
inch :	27.56	19.69	12.2

**Materials :**

Material : Polycarbonate

**Accessories :**

MPX ARCA 7050	Mounting plate (630x430 mm) (630 x 430 x 8)
PMK ARCA 70	PoleMounting kit, for pole $\varnothing$ 100-300mm (685 x 485 x 35)
RCS ARCA 5070	Rain canopy set for size 5070
DSP ARCA RM	Door stopper ARCA, right, midsize 5070-8060

Base colour :	RAL_7035
Cover colour :	Clear transparent
Gasket material :	Polyurethane

DRS ARCA 507030	DIN rail frame set (685 x 485 x 35)
--------------------	--

IDS ARCA 5070	Inner door set
------------------	----------------

DSP ARCA LM	Door stopper ARCA, left, midsize 5070-8060
-------------	--

MPS ARCA 7050	Mounting plate (630x430x2 mm) (630 x 430 x 2)
------------------	--

MPMP ARCA 7050	Mounting plate multiperforated (630x430x2 mm - ø3.6 mm)
-------------------	---

MPP ARCA 5070	Mounting plate perforated (630x430x2 mm - 26x11 mm)
------------------	---

**Temperatures :**

Temperature °C (continuous) :	-40 ... 80
-------------------------------	------------

Temperature °F (continuous) :	-40 ... 175
-------------------------------	-------------

**Ratings :**

Ingress protection (EN 60529):	IP65;
--------------------------------	-------

Impact Resistance (EN 62262):	IK08;
-------------------------------	-------

electrical_insulation :	Totally insulated
-------------------------	-------------------

Halogen free (DIN/VDE 0472, Part 815) :	Yes
---	-----

UV resistance :	UL 746C
-----------------	---------

Flammability Rating :	UL 94 5VA
-----------------------	-----------

Glow Wire Test (IEC 695-2-1) °C :	960C
-----------------------------------	------

**Certificates :**

Certificate FI 40467