


# MPMP ARCA 3030

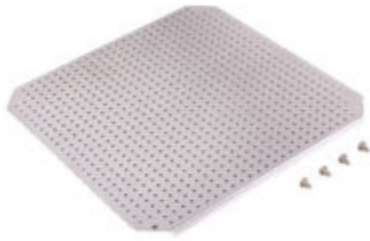

Sample image

**Order symbol:** MPMP ARCA 3030

**Product nbr:** 8120921

**Description:** Mounting plate  
multiperforated (250x250x2 mm -  
ø3.6 mm)

**Remarks:** Galvanized steel. for size  
300x300x210

**Including:**

**EAN:** 6418074089489

**EI. number:**

- Finland: 3424535
- Denmark:
- Sweden:

| <b>Dimensions:</b> | <b>Length</b> | <b>Width</b> | <b>Height</b> |
|--------------------|---------------|--------------|---------------|
|--------------------|---------------|--------------|---------------|

|     |     |     |  |
|-----|-----|-----|--|
| mm: | 250 | 250 |  |
|-----|-----|-----|--|

|       |      |      |  |
|-------|------|------|--|
| inch: | 9.84 | 9.84 |  |
|-------|------|------|--|

**Materials:**

Material:

Base colour:

Cover colour:

Gasket material:

**Temperatures:**

Temperature °C (short term):

Temperature °C (continuous):

Temperature °F (short term):

Temperature °F (continuous):

**Rating:**

Ingress protection (EN 60529):

Impact Resistance (EN 62262):

Electrical insulation: Not insulated

Halogen free (DIN/VDE 0472, Part 815): 0

UV resistance: -

Flammability Rating:

Glow Wire Test (IEC 695-2-1) °C:

NEMA Class

**Certificates:**