


## Datasheet

# ANSI PVC Thermocouple Extension & Compensating Cable

PVC Insulated Flat Pair (ANSI MC96.1)

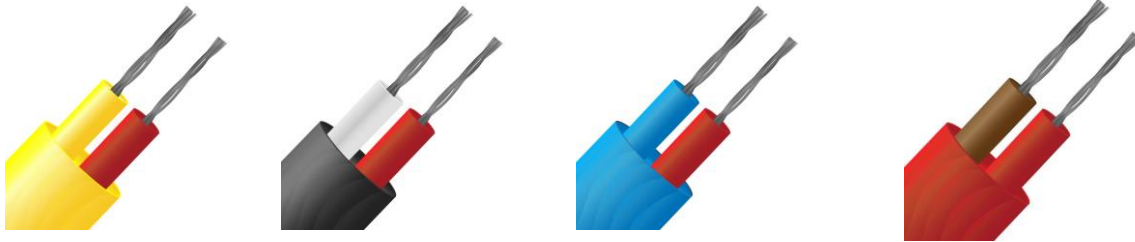

- PVC insulated flat pair construction
- Conductors laid flat PVC insulated with overall PVC sheath
- All round general purpose cable, both waterproof and very flexible
- Thermocouple extension types for K, J, & T
- Compensating types VX (KCB) for types K Thermocouples
- Stranded conductors available, 7/0.2mm
- Available in multiple reel lengths
- Tolerance Class 2
- Insulation rating -10°C to 105°C
- Colour code (cores & jacket) to ANSI MC96.1

T/C Type	Conductors	Cores	Jacket	Reel Length	RS order code
<b>Extension:</b>					
KX	7/0.2mm	+Yellow/-Red	Yellow	10m	<b>2154896</b>
KX	7/0.2mm	+Yellow/-Red	Yellow	25 m	<b>8140018</b>
KX	7/0.2mm	+Yellow/-Red	Yellow	50 m	<b>2154895</b>
KX	7/0.2mm	+Yellow/-Red	Yellow	100 m	<b>8140027</b>
KX	7/0.2mm	+Yellow/-Red	Yellow	200 m	<b>8140020</b>
JX	7/0.2mm	+ White/-Red	Black	10 m	<b>2154869</b>
JX	7/0.2mm	+ White/-Red	Black	25 m	<b>8139995</b>
JX	7/0.2mm	+ White/-Red	Black	50 m	<b>2154870</b>
JX	7/0.2mm	+ White/-Red	Black	100 m	<b>8140005</b>
JX	7/0.2mm	+ White/-Red	Black	200 m	<b>8140008</b>
TX	7/0.2mm	+Blue/-Red	Blue	25 m	<b>8140074</b>
TX	7/0.2mm	+Blue/-Red	Blue	100 m	<b>8140083</b>
TX	7/0.2mm	+Blue/-Red	Blue	200 m	<b>8140086</b>
<b>Compensating:</b>					
VX (KCB)	7/0.2mm	+Brown/-Red	Red	10 m	<b>2154936</b>
VX (KCB)	7/0.2mm	+ Brown /-Red	Red	25 m	<b>8140103</b>
VX (KCB)	7/0.2mm	+ Brown /-Red	Red	50 m	<b>2154937</b>
VX (KCB)	7/0.2mm	+ Brown /-Red	Red	100 m	<b>8140112</b>
VX (KCB)	7/0.2mm	+ Brown /-Red	Red	200 m	<b>8140115</b>