

## Datasheet

# RS Pro 400W DC-AC Power Inverter Modified sine, 24V dc / 230V ac

Stock number: 816-0030

RoHS 







### Specifications:

Model	816-0030
Rated power	400W
Surge power	800W
Output voltage	230V
Output frequency	50Hz $\pm$ 3
Output waveform	Modified sine wave
USB port	5V 2.1A
Input voltage	24V
Dimension(LxWxH)	195x102x55.5mm
N.W/unit	630g

### Features:

- Anodized aluminum case provides durability & max heat dissipation
- Two LED indicators on the front panel shows the working and failure state
- ON/OFF switch control the inverter by hand
- The inverter is compact, light weight and east to operate.
- Protections: overheat, overload, low-voltage alarm & shutdown, over-voltage, short circuit, reverse polarity
- Soft start
- Auto. Reset after being in protected
- Universal UK/Euro output socket:

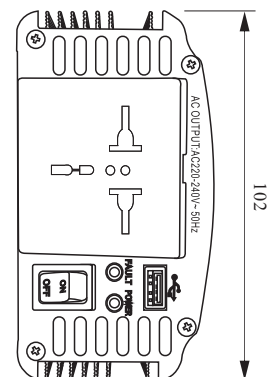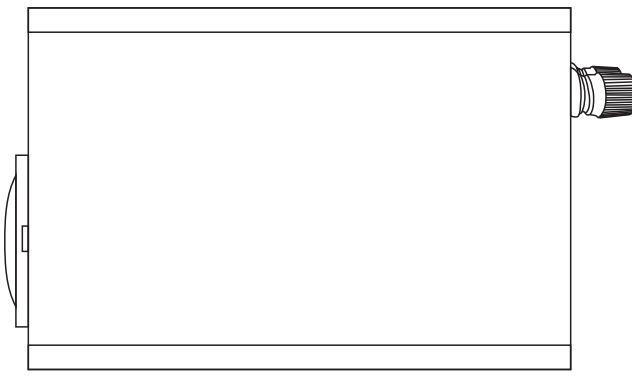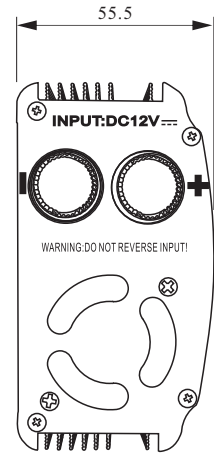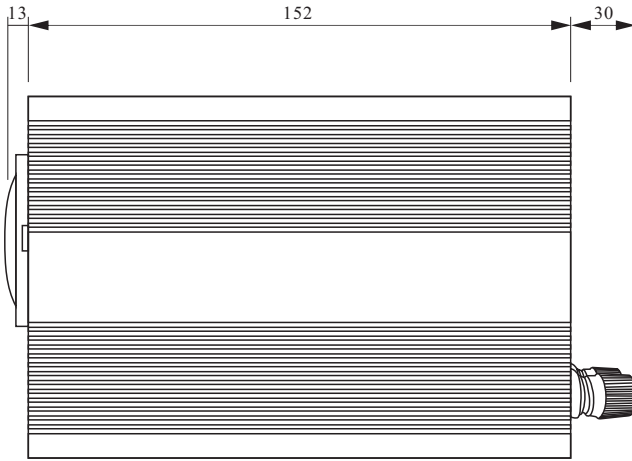

Unit: mm



rspro.com

