

**Datasheet**

Art.No. 83.040.0001.0

IP switch WIENET UMS 8

wieNET IP Switch, 8 TP-RJ45-Ports, transfer rate 10/100 MBit/s, unmanaged switch, Autonegotiation, Autosensing, Autocrossing-function, redundant power supply, supply voltage: 9-48 V, vertical mount



Art.No.	83.040.0001.0
EAN	4049088081941
Order unit	1 pieces

**Approvals**



**Technical data**

**Allgemein**

Mounting method	DIN rail (top hat rail)
Degree of protection (IP)	IP50
Diagnostic LEDs	Power/Link status/Data/Data rate
Ethernet	Yes
Power over Ethernet	No
Fast Ethernet	Yes
Gigabit Ethernet	No
Number of ports 10/100 Mbps RJ45	8
10 Gigabit Ethernet	No
Number of ports 10/100/1000 Mbps RJ45	0
Number of ports 100 Mbps SC	0
Number of 100 Mbps ST-Ports	0

**Technical data**

Voltage type	DC
Min. operating temperature	-10 °C
Max. operation temperature	60 °C
Redundant power supply	2 power inputs

**Supply circuit**

Voltage type	DC
Operating voltage min.	9 V
Operating voltage max.	30 V


**Dimensions**

Depth	80 mm
Width	45 mm
Height	91 mm

**Classification**

ECLASS 8.1	19170106: Network switch
ETIM 5.0	EC000734: Network switch
ETIM 4.0	EC000734: Network switch
ETIM 3.0	EC000734: Network switch

Drawings

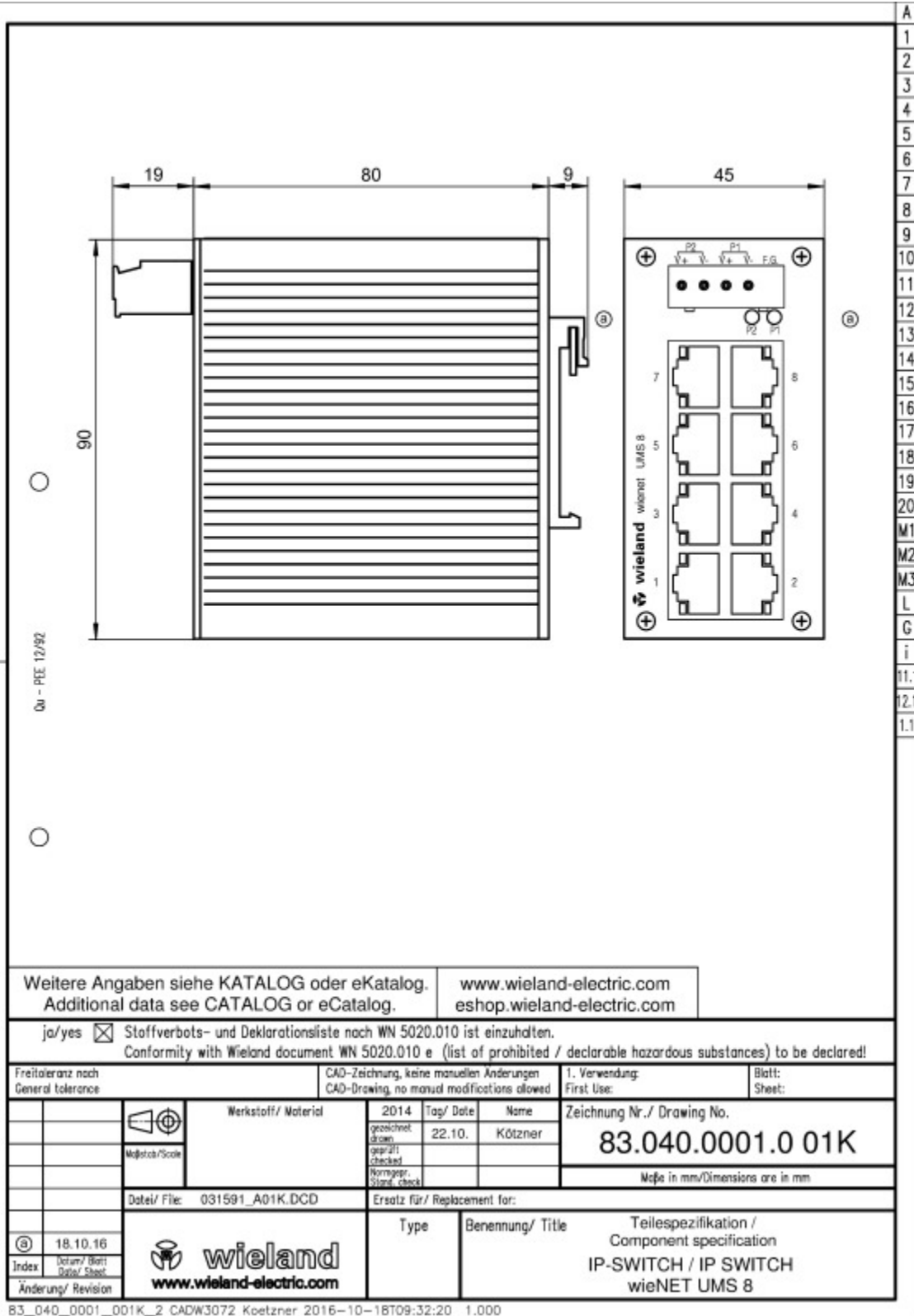

B3\_040\_0001\_001K\_2 CADW3072 Koetzner 2016-10-18T09:32:20 1.000