

FEATURES

- Great protection for wiring looms and harnesses
- Enclosing fiberoptics
- Fast protection on loose cables
- Route wiring in control panels
- Run wire through cabinets, cars and machines

RS PRO Plastic Flexible, Split Conduit Black 20mm x 100m

RS Stock No.: 875-0258



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

Introducing the RS Pro range of flexible split conduit, created and designed for the protection and structure of running electrical wiring through machinery or buildings. Split conduit is a strategic choice for users who are looking to enclose cables in a tidy fashion or needing to repair damaged conduit.

General Specifications

Conduit Type	Flexible, Split
Material	Plastic
Colour	Black

Mechanical Specifications


Nominal Diameter	20mm
Outer Diameter	19.5mm
Interior Diameter	15mm
Length	100mm

Operation Environment Specifications

Maximum Operating Temperature	+80°C
Minimum Operating Temperature	-20°C

Approvals

Compliance/Certifications	2011/65/EU and 2015/863
Standards Met	RoHS Compliant

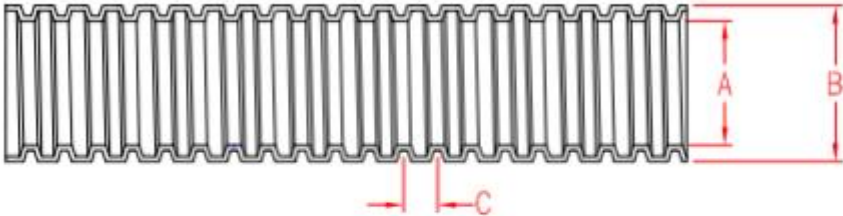

Dimensions – mm