

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0901230110](#)
Status: **Active**
Description: 2.54mm Pitch C-Grid III Modular Crimp Housing Single Row, 2 Polarizing Buttons, 10 Circuits, Black

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)
[Product Specification PS-99020-0001-001 \(PDF\)](#)
[Packaging Specification PK-90123-0001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification
UL

E29179

General

Product Family: Crimp Housings
Series: [90123](#)
Application: Signal
Comments: 2 Polarizing Buttons, 2 Polarizing Buttons
Product Name: C-Grid III
UPC: 800753706453


Physical

Circuits (maximum): 10
Color - Resin: Black
Flammability: 94V-1
Gender: Receptacle
Glow-Wire Capable: No
Material - Resin: PPO
Net Weight: 0.576/g
Number of Rows: 1
Packaging Type: Bag
Panel Mount: No
Pitch - Mating Interface: 2.54mm
Stackable: Yes
Temperature Range - Operating: -55° to +105°C

Material Info

Reference - Drawing Numbers

Packaging Specification: PK-90123-0001
Product Specification: PS-99020-0001-001
Sales Drawing: SD-90123-001

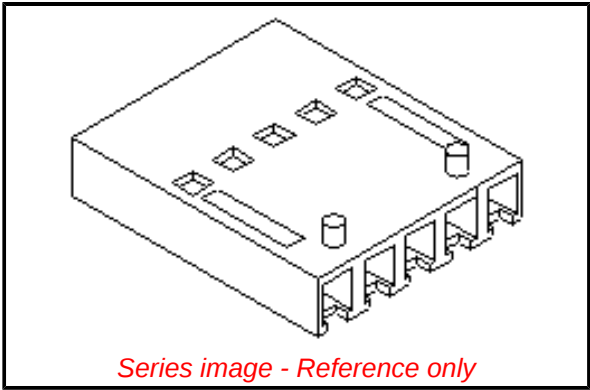

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

China RoHS

REACH SVHC

Not Contained Per -
ED/30/2017 (7 July
2017)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[90123](#) Series

Mates With

C-Grid III Header [90120](#) , [90121](#) , C-Grid III Header [90136](#)

Use With

C-Grid III Crimp Terminal [90119](#)