

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0901560143](#)
Status: **Active**
Overview: [C-Grid III Interconnects](#)
Description: 2.54mm Pitch C-Grid III Crimp Housing Single Row, 3 Circuits, Black

Documents:

[3D Model](#) [Packaging Specification PK-90156-0001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-99020-0001-001 \(PDF\)](#)

Agency Certification

CSA LR19980
 UL E29179

General

Product Family Crimp Housings
 Series [90156](#)
 Application Signal, Wire-to-Board
 Overview [C-Grid III Interconnects](#)
 Product Name C-Grid III
 UPC 800753668140


Physical

Breakaway No
 Circuits (maximum) 3
 Color - Resin Black
 Gender Receptacle
 Glow-Wire Capable No
 Lock to Mating Part Yes
 Material - Resin PPO
 Net Weight 0.293/g
 Number of Rows 1
 Packaging Type Bag
 Panel Mount No
 Pitch - Mating Interface 2.54mm
 Temperature Range - Operating -55° to +105°C

Material Info

Reference - Drawing Numbers

Packaging Specification PK-90156-0001
 Product Specification PS-99020-0001-001
 Sales Drawing SDA-90156

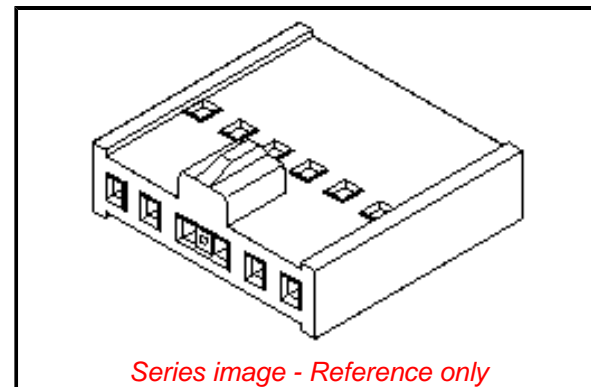

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per
 -ED/88/2018 (15
 January 2019)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[90156](#) Series

Mates With

[90120](#) , [90121](#) , [90136](#)

Use With

[90119](#)