

## FEATURES

- EMC approved (ECE R10)
- Sealed for life against dust and moisture ingress
- Meets IP67 protection standards
- • -30 to +50° ( extreme temperature
- Low power consumption
- Providing excellent all-round visibility

## RS PRO Amber LED Beacon, 10 → 100 V dc, Flashing, Screw Mount

RS Stock No.: 907-5961



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

### Product Description

These Low Profile LED Beacons from our own RS PRO brand is ideal for off-road use and is also suitable for a variety of vehicles and industrial applications. The use of LED technology offers substantial maintenance savings by avoiding the need for regular lamp replacement which could be tricky on higher vehicles.

### General Specifications

<b>Bulb Type</b>	LED
<b>Light Effect</b>	Flashing
<b>Lens Colour</b>	Amber
<b>Flash Pattern</b>	Static , Single, Double ,Quad
<b>Housing Colour</b>	Black
<b>Lamp Include</b>	Yes
<b>Multifunction</b>	Yes
<b>Number of flash patterns</b>	4
<b>Number of LED</b>	4
<b>Special Features</b>	Fully Encapsulated Electronics, Low Power Consumption

### Electrical Specifications

<b>Supply Voltage</b>	10VDC to 100 VDC
<b>Current Type</b>	DC

**Mechanical Specifications**

<b>Dimensions</b>	99 (w) x 77(d) x 45mm (h)
<b>Base Diameter</b>	77mm
<b>Mounting Style</b>	Screw Mount
<b>Weight</b>	0.13kg

**Operation Environment Specifications**

<b>Maximum Temperature</b>	-30°C
<b>Minimum Temperature</b>	+50°C



**Protection Category**

<b>IP Rating</b>	IP 67
------------------	-------

**Approvals**

<b>Standards Met</b>	EMC (ECE R10), RoHS Compliant
----------------------	-------------------------------



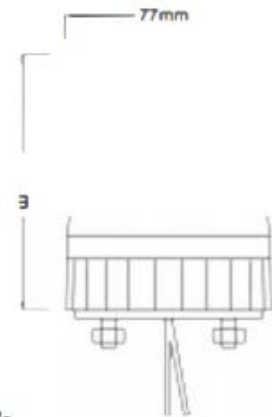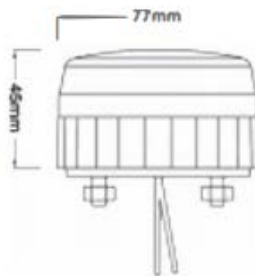

**10-100Vdc**

- AMBER** RS 907-5961
- RED** RS 907-5965
- GREEN** RS 907-5974

**110-230Vac**


- AMBER** RS 907-5977
- RED** RS 907-5971

**10-100Vdc**

- AMBER** RS 907-5980
- RED** RS 907-5983
- GREEN** RS 907-5987

**110-230Vac**

- AMBER** RS 907-5996
- RED** RS 907-5999

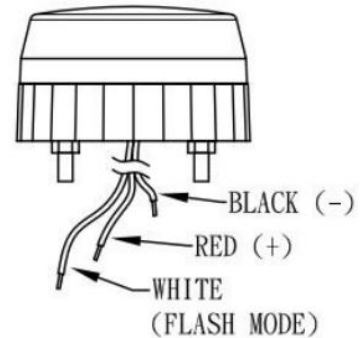

- › Operating Voltage: 10V-130V DC
- › Current Draw: Max 0.1 Amps @ 12VDC
- › SMT 5050 3-CHIP PLCC LED
- › Working Temperature: -25°C ~ 75°C
- › Colour: Amber, Red, Blue, Green And Clear LED or Lens
- › Flash Mode:
  1. Quad (60 FPM)
  2. Double (90 FPM)
  3. Single (120 FPM)
  4. Static ON
- › To change the flash mode ,bridge white and red wires for 0.5 second to 1 second.
- › Connect white and red wires over 1 second, the light will stay on Static Mode.