





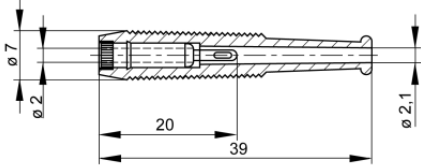


Sockets

MKU 1



Product	MKU 1
description	2 mm diameter miniature coupling, insulated, tin-plated copper beryllium contact spring with solder connection. Flexible, shatter-proof insulated sleeve. For making up connecting leads with a maximum external diameter of 2 mm.
operating instruction	BA206
article-no. / *colour	9303201xx <div style="display: flex; justify-content: space-around; align-items: center;"> <div style="text-align: center;"> 00 black</div> <div style="text-align: center;"> 01 red</div> <div style="text-align: center;"> 02 blue</div> <div style="text-align: center;"> 03 yellow</div> <div style="text-align: center;"> 04 green</div> <div style="text-align: center;"> 07 white</div> </div> <div style="text-align: right; margin-top: 5px;">Sn</div>
drawing	
technical data	
connection	solder connection
rated voltage	30 VAC / 60 VDC
rated current (consider derating curve)	6 A
material socket	contact spring: copper - beryllium
housing material	PVC-P
temperature range acc. To IEC61010 ⁽¹⁾	-20°C °C to +60°C °C

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges
stand: 02.02.2023

stand: 02.02.2023

2 mm system