
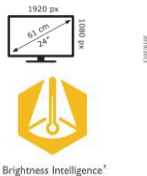


# Data sheet

## BenQ BL2480T

60.45 cm / 23.8" LED-Display

- FHD IPS Panel
- Height Adjustment incl. Pivot
- Color Weakness Mode
- Brightness Intelligence

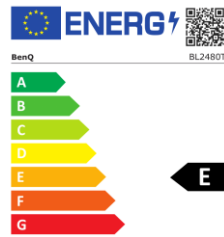

**Panel**  
Model : BL2480T  
Art. No. / EAN Code : 9H.LHFLA.FBE / 471 8755 07625 1  
Type : 60.45 cm / 23.8" Wide TFT, IPS-Panel  
Resolution : 1920 x 1080 / 16:9  
Pixel Pitch : 0,274 mm  
Picture diagonal / -area (w x h) : 604,5 mm / 527.04 x 296.46 mm  
Max. Colors : 16.7 Million  
Viewing Angle H/V (CR>=10) : 178°/ 178°  
Contrast (static) : 1000:1  
Contrast (dynamic) : 20 million:1  
Brightness : 250 cd/m<sup>2</sup>  
Response Time : 5 ms (GtG)

**Connection:**  
HDMI Connector : 1x HDMI 1.4  
D-Sub Connector : 1x VGA  
DisplayPort Connector : 1x DP 1.2  
Headphone Jack / Audio out : Yes / Yes  
Frequency H/V : 30-83 KHz / 50-76 Hz

**Control**  
Controls : On/Off power button, 5 OSD buttons  
Functions : contrast, brightness, sharpness, vertical and horizontal picture, phase, pixel clock, 1 user 3 pre-settings color temperature, 17 languages, OSD (position, time), input, reset, information

**Extra**  
Special : Flicker Free, Low Blue Light, Brightness Intelligence, Color Weakness  
Speaker : 1W x 2  
Protection : Kensington Lock  
Mounting : Vesa 100 x 100 mm  
Height Adjustment : 140 mm incl. Pivot  
Tilt : -5° / +20°

**Energy**  
Power Supply : internal  
Voltage for operation : 100V – 240V / 50Hz – 60Hz  
Power consumption (Base on Energy star) : 16 W  
Power consumption (On Mode) : 27 W  
Power consumption (Off Mode) : 0.5 W

**Certification**  
Safety : CE  
Ergonomics : TÜV Bauart, TCO 7.0  
Environment : Energy Star 7.0, EPEAT Silber

**Environment**  
Operation : + 5 ~ +40°C; 20 ~ 90% air humidity  
Storage : -20 ~ +60°C; 10 ~ 90% air humidity

**Characteristic**  
Weight net : 5.7 kg  
Housing Color : Black  
Dimension with base / w/o base (H x W x D) : 528 x 540 x 230 / 340 x 540 x 50 mm  
Accessories : Power-, DP- cable

Warranty Terms : 3 years on-site exchange

