

# Product datasheet

Specifications



## plate for mounting on symmetrical DIN rail - for voltage transformer

ABL6AM02

### Main

|                                    |                                 |
|------------------------------------|---------------------------------|
| Range of product                   | Phaseo                          |
| Accessory / separate part type     | Plate for mounting on rail      |
| Accessory / separate part category | Mounting and fixing accessories |
| Quantity per set                   | Set of 5                        |

### Complementary

|                                       |                            |
|---------------------------------------|----------------------------|
| Accessory / separate part destination | Transformer: ABL6TS 63 VA  |
| Product mounting                      | 35 mm symmetrical DIN rail |
| Height                                | 78 mm                      |
| Width                                 | 74 mm                      |
| Net weight                            | 0.055 kg                   |

### Packing Units

|                              |          |
|------------------------------|----------|
| Unit Type of Package 1       | PCE      |
| Number of Units in Package 1 | 1        |
| Package 1 Weight             | 68.0 g   |
| Package 1 Height             | 1.0 cm   |
| Package 1 width              | 7.8 cm   |
| Package 1 Length             | 7.8 cm   |
| Unit Type of Package 2       | S01      |
| Number of Units in Package 2 | 48       |
| Package 2 Weight             | 3.546 kg |
| Package 2 Height             | 15.0 cm  |
| Package 2 width              | 15.0 cm  |
| Package 2 Length             | 40.0 cm  |

### Offer Sustainability


|                          |                                   |
|--------------------------|-----------------------------------|
| Sustainable offer status | Green Premium product             |
| REACH Regulation         | <a href="#">REACH Declaration</a> |

|                                   |                                                                                                   |
|-----------------------------------|---------------------------------------------------------------------------------------------------|
| <b>REACH free of SVHC</b>         | Yes                                                                                               |
| <b>EU RoHS Directive</b>          | Pro-active compliance (Product out of EU RoHS legal scope)<br><a href="#">EU RoHS Declaration</a> |
| <b>Toxic heavy metal free</b>     | Yes                                                                                               |
| <b>Mercury free</b>               | Yes                                                                                               |
| <b>RoHS exemption information</b> | <a href="#">Yes</a>                                                                               |
| <b>China RoHS Regulation</b>      | <a href="#">China RoHS declaration</a>                                                            |
| <b>Environmental Disclosure</b>   | <a href="#">Product Environmental Profile</a>                                                     |
| <b>PVC free</b>                   | Yes                                                                                               |

### **Contractual warranty**

|                 |           |
|-----------------|-----------|
| <b>Warranty</b> | 18 months |
|-----------------|-----------|

**Dimensions**

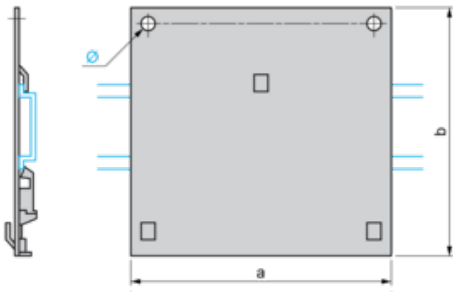

Dimensions in mm

| a  | b  | Ø |
|----|----|---|
| 78 | 74 | 4 |

Dimensions in in.

| a    | b    | Ø    |
|------|------|------|
| 3.07 | 2.91 | 0.16 |