



STANDARD 12 KEYPAD

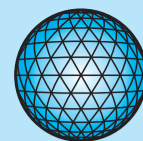

APEM

3+4 MATRIX KEYPAD WITH INSERT POCKETS

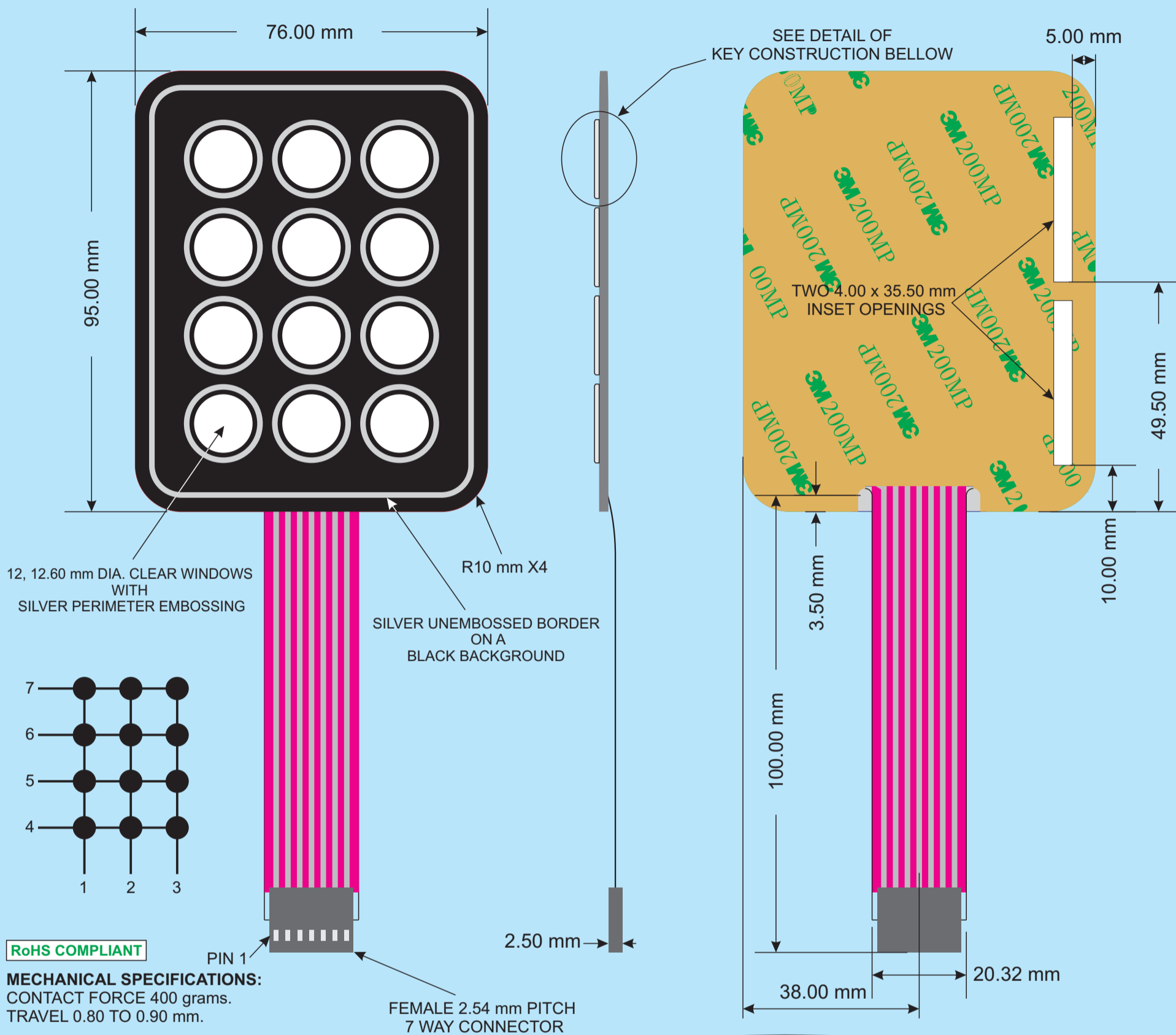


RoHS COMPLIANT




MECHANICAL SPECIFICATIONS:
 CONTACT FORCE 400 grams.
 TRAVEL 0.80 TO 0.90 mm.

ELECTRICAL SPECIFICATIONS:
 CONTACT VOLTAGE RATING 30V (dc).
 CONTACT CURRENT RATING 100mA.
 INSULATION RESISTANCE AT 100 V >100 Mohms.
 DIELECTRIC STRENGTH 250 V rms.
 CAPACITANCE 10 pF typ.
 CONTACT BOUNCE BELOW 10 msec. typ.

ENVIRONMENTAL SPECIFICATIONS:
 OPERATING TEMPERATURE -30 TO +55 C.
 STORAGE TEMPERATURE -40 TO +60 C.

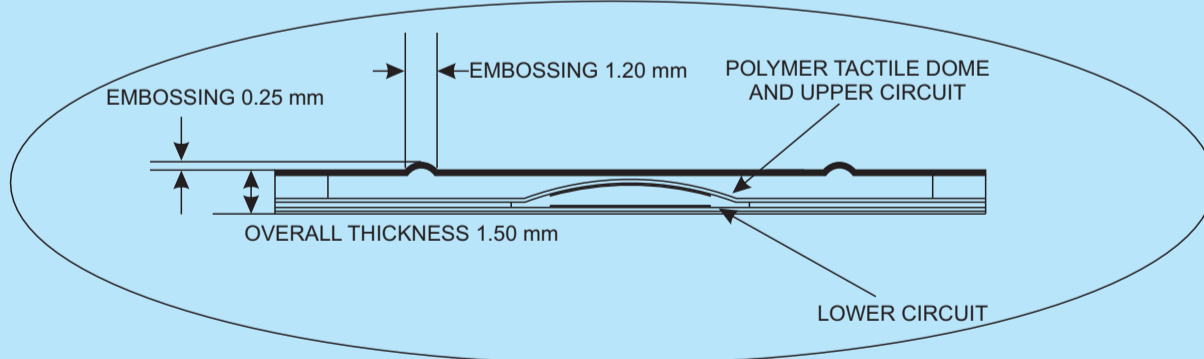

4 INSERTS WITH BLACK GRAPHICS ON A SILVER BACKGROUND
 SUPPLIED WITH THIS KEYPAD. FOR OTHER VARIANTS OF INSERTS PLEASE CALL APEM

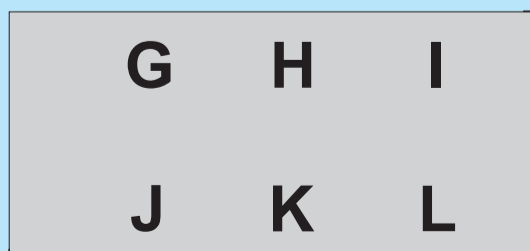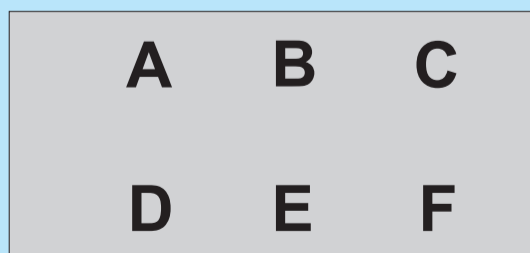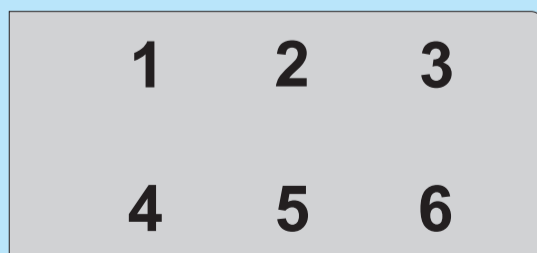

R. 1.50mm ON 2 CORNERS

70.50 mm

33.00 mm