



LMK-01



Improve space utilisation in any environment with AG Neovo LMK-01 Wall Mount Kit for large-sized displays.

The high quality LMK-01 housed with anodised steel is rust resistant and suitable for both brick and stud walls. Compliant with universal VESA standards, it can accommodate displays from 32" up to 65" displays weighing up to 100 kg. The LMK-01 is desirable for indoor and outdoor environments including retail, health centre, lobbies, digital signage and other public places where saving space is a priority.

- > High quality steel construction for strength and durability
- > Anodised surface prevents rust
- > Flexible tilting for better viewing experience
- > Suitable for both brick and stud walls
- > Lockable safety bar (padlock not included)
- > VESA standard design
- > Accommodate LCD displays from 32" up to 65" displays
- > Support up to 100 kg (220 lbs)

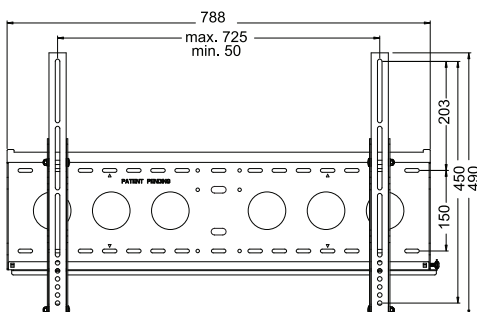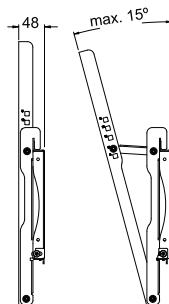

Specifications

Mounting	Display VESA Standard	32" -65" VESA Standard Max. 725 x 450 mm
Loading	Weight Capacity	up to 100 kg (220 lbs)
Tilt	Down	15°
Exterior	Material Colour	Steel Black
Dimensions	Product (W x H x D) Packaging (W x H x D)	788 x 490 x 48 mm 836 x 245 x 54 mm
Weight	Product Weight Packaged Product Weight	5.1 kg (11.2 lbs) 5.9 kg (13.0 lbs)
Packing	1 Carton 1 Pallet	1 Set 140 pc
Accessories	Supplied	User Manual, plastic plug (6 pcs), lag blot (6 pc), screw for display housing (4 pcs), plastic washer (4 pcs), arm (2 pcs), carriage bolt (2 pcs), flat washers (4 pcs), nylon nut (4 pcs)