


## Power Cord, C13 to C14, 2.5m

AP9870

Call for More Information 0800 2799254

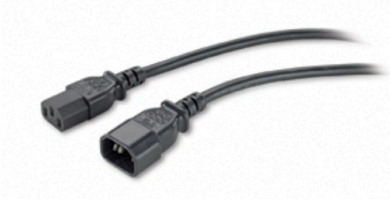

Output	
Overload Protection	No
Maximum Total Current Draw	10
Output Connections	(1) IEC 60320 C13 (1) IEC 320 C13

Input	
Input frequency	50/60 Hz
Input Connections	IEC 60320 C14
Cord Length	2.5meters
Acceptable Input Voltage	90 - 250VAC
Number of Power Cords	1
Maximum Input Current	10A
Maximum Line Current	10A

Physical	
Maximum Height	38MM, 3.8CM
Maximum Width	76MM, 7.6CM
Maximum Depth	203MM, 20.3CM
Net Weight	0.23KG
Shipping weight	0.3KG
Shipping Height	51MM, 5.1CM
Shipping Width	102MM, 10.2CM

Disclaimer: Documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user's applications.

## Technical Specifications

Power Cord, C13 to C14, 2.5m | AP9870 | Downloaded on 02/25/2022 (EST)

Physical	
Shipping Depth	203MM, 20.3CM
Color	Black
Units per Pallet	600.0

Environmental	
Operating Temperature	0 - 45 °C
Operating Relative Humidity	0 - 95 %
Operating Elevation	0 - 3048meters
Storage Temperature	-25 - 65 °C
Storage Relative Humidity	0 - 95 %
Storage Elevation	0 - 15240meters

Conformance	
Approvals	CSA, UL listed, VDE
Standard warranty	2 years repair or replace

Sustainable Offer Status	
RoHS	Compliant

**Disclaimer:** Documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user's applications.