


Technical Specifications

APC Easy Rack, 42U, Black, With Roof, Castors, Feet, 4 Brackets, and Bottom, No Side Panels, 1991H x 600W x 1200D mm | ER6220 |
Downloaded on 10/03/2022 (EST)

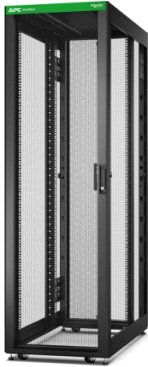

APC Easy Rack, 42U, Black, With Roof, Castors, Feet, 4 Brackets, and Bottom, No Side Panels, 1991H x 600W x 1200D mm

ER6220

Call for More Information 0800 2799254

- Includes: Baying hardware, Doors, Key(s), Leveling feet, Mounting hardware, Pre-installed casters

Physical	
Maximum Height	1991MM, 199.1CM
Maximum Width	600MM, 60.0CM
Maximum Depth	1200MM, 120.0CM
Rack Height	42U
Net Weight	77.6KG
Shipping weight	85.0KG
Shipping Height	2120MM, 212.0CM
Shipping Width	1250MM, 125.0CM
Shipping Depth	650MM, 65.0CM
Color	Black
Maximum Mounting Depth	1041.0MM, 104.14CM
Minimum Mounting Depth	191.0MM, 19.05CM
Front Door	18.0gauge
Vertical Posts	16.0gauge
Rear Door	19.0gauge
Rack Width	19"
Weight Capacity (static load)	1199.75KG
Weight Capacity (dynamic load)	599.65KG
Conformance	
Approvals	EIA-310E, UL 2416, UL 60950-1

Disclaimer: Documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user's applications.

Technical Specifications

APC Easy Rack, 42U, Black, With Roof, Castors, Feet, 4 Brackets, and Bottom, No Side Panels, 1991H x 600W x 1200D mm | ER6220 |
Downloaded on 10/03/2022 (EST)

Conformance	
Standard warranty	5 year repair or replace

Sustainable Offer Status	
RoHS	Compliant

Disclaimer: Documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user's applications.