


Product data sheet

Specifications

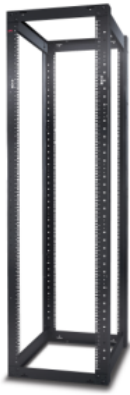

NetShelter 4 Post Open Frame Rack 44U Square Holes

AR203A

Overview

Lead time Usually in Stock

Main

Number of rack unit 44U

Provided equipment Installation guide

Physical

Color Black

Height 83.86 in (213 cm)

Width 23.62 in (60 cm)

Depth 29.41 in (74.7 cm)

Net Weight 89.09 lb(US) (40.41 kg)

Mounting Location Front
Rear

Mounting preference No preference

Mounting Mode Not rack-mountable

Maximum Mounting Depth 29.13 in (73.99 cm)

Minimum Mounting Depth 29.13 in (73.99 cm)

Rack Width 19"

Permanent permissible load 2000 lb(US) (907.18 kg) static

Conformance

Standards EIA-310E

Ordering and shipping details

GTIN 731304260233

Packing Units

Unit Type of Package 1 PCE

Number of Units in Package 1 1

Package 1 Height 82.01 in (208.3 cm)

Package 1 Width	4.45 in (11.3 cm)
Package 1 Length	10.00 in (25.4 cm)
Package 1 Weight	89.99 lb(US) (40.82 kg)

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	Yes
Take-back	Take-back program available

Contractual warranty

Warranty	5 year repair or replace
-----------------	--------------------------

Recommended replacement(s)