


Product information

ASBSV 8/LED 5

Industrial Connecting Solutions:I/O Modules:Passive distributors:M12 Passive Distributors:pluggable:with LED:2 signals/socket (4+PE):8-ports:ASBSV 8/LED 5

<https://www.e-catalog.beldensolutions.com:443/link/57078-24228-255441-199791-200292-204939-204943-204957-205274-205284/en/conf/ulistate>


Name	ASBSV 8/LED 5
	
	Pluggable actuator/sensor distribution box, 8 port version, with LED operation and function indicators, combined FIXCOM/M12 socket, 5-pole, 2 signals per socket, earth connection, M23 connection for the control cable.
Delivery informations	
Availability	available
Product description	
Type	ASBSV 8/LED 5
Order No.	11138
Description	Pluggable actuator/sensor distribution box, 8 port version, with LED operation and function indicators, combined FIXCOM/M12 socket, 5-pole, 2 signals per socket, earth connection, M23 connection for the control cable.
Number of contacts	5 (M12)
Version	8 ports
Color of housing	orange
Product characteristics	Vibration resistance, Oil resistance
Classification	
Belden brand	Lumberg-Automation
Mechanical data	
Thread	M12
LED display present	✓
Environmental conditions	
Environmental temperature	-15 °C ... 80 °C
Degree of protection (IP), mounted	IP67
Pollution degree	3
Materials	
Housing material / Molded body	TPU, self-extinguishing
Contact bearer material	PA-GF, self-extinguishing
Contact material	CuZn
Contact material - Surface refinement	pre-nickel and 0.8 microns gold-plated
Knurled screw / nut material	CuZn, nickel-plated
Sealing material	FKM
Electrical data	
Contact resistance	≤ 5 mΩ
Rated current In	4 A per socket / 10 A max. at 40°C
Nominal voltage	10 - 30 V DC
Rated voltage	32 V
Insulation resistance	> 1 GΩ
Approvals	
Approvals	cURus
Scope of delivery and accessories	
Scope of delivery	ZVK: 2 dust covers for unused sockets ZBS: 10 attachable labels

Industrial Connecting Solutions:I/O Modules:Passive distributors:M12 Passive Distributors:pluggable:with LED:2 signals/socket (4+PE):8-ports:ASBSV 8/LED 5

<https://www.e-catalog.beldensolutions.com:443/link/57078-24228-255441-199791-200292-204939-204943-204957-205274-205284/en/conf/uistate>

Picture

Drawing

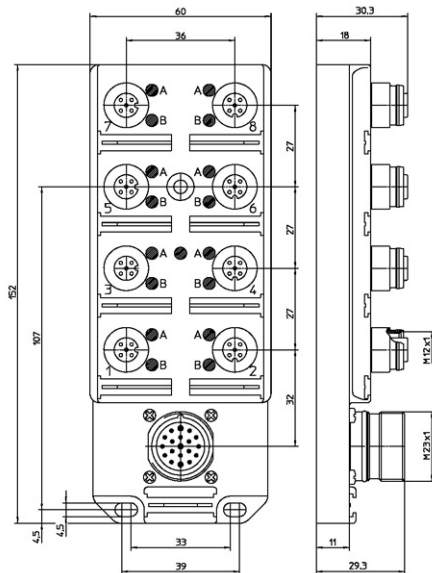

Belden Deutschland GmbH
 Im Gewerbepark 2
 58579 Schalksmühle
 Germany
 Phone: +49 7127/14-1806
 E-Mail: icos-sales@belden.com

The information published in the websites has been compiled as carefully as possible. It is subject to alteration without notice in technical as well as in price-related/commercial respect. The complete information and data were available on user documentation. Mandatory information can only be obtained by a concrete query.