




DIN 7981 C

~ISO 7049

450 HV

Standard withdrawn

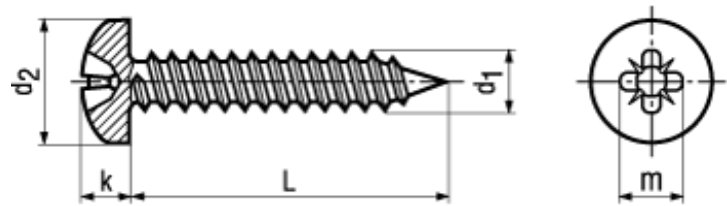

BN 14064

Pozi pan head tapping screws

form Z, with cone end type C

Steel case-hardened 450 HV

zinc plated blue


- ~UNI 6954 AB
- ~ČSN 021235





ISO 4042

Fasteners hardness ≥ 320 HV with electroplated coatings:
Susceptible to hydrogen embrittlement!

Further notice to residual risks can be found in the introduction section.

Article#	d ₁	d ₂ max.	k max.		m~	L
2097567	ST 2,2	4,2	1,8	1	2,4	4,5
2097575						6,5
2097583						9,5
2097591						13
2097605						16
5000432	ST 2,9	5,6	2,2	1	2,9	4,5
2097613						6,5
5000440						8
2097621						9,5
2097648						13
2097656						16
2097664						19
2097672						25
2097680						32
2097699						38
2097702	ST 3,5	6,9	2,6	2	3,9	6,5
5000467						8
2097710						9,5
2097729						13
2097737						16
2097745						19
2097753						25
2097761						32
2097788						38
8042896	(ST 3,9)	7,5	2,8	2	4,1	6,5
2097796						9,5

Article#	d ₁	d ₂ max.	k max.		m~	L
2097818	(ST 3,9)	7,5	2,8	2	4,1	13
2097826						16
2097834						19
2097842						25
2097850						32
2097869						38
2097877						45
5000483	ST 4,2	8,2	3,05	2	4,3	8
2097885						9,5
2097893						13
2097907						16
2097915						19
5000475						22
2097923						25
2097931						32
2097958						38
2097966						45
2097974						50
2097982	ST 4,8	9,5	3,55	2	4,7	9,5
2097990						13
2098008						16
2098016						19
2098024						25
2098032						32
2098040						38
2098059						45
2098067						50
2098075	ST 5,5	10,8	3,95	3	6,2	13
2098083						16
2098091						19
2098105						25
2098113						32
2098121						38
2098148						45
2098156						50
2098164	ST 6,3	12,5	4,55	3	6,7	13
2098172						16
2098180						19
2098199						25
2098202						32
2098210						38

Article#	d ₁	d ₂ max.	k max.		m~	L
2098229	ST 6,3	12,5	4,55	3	6,7	45
2098237						50