




ISO 14580

08.8 / 8.8

The head marking is determining

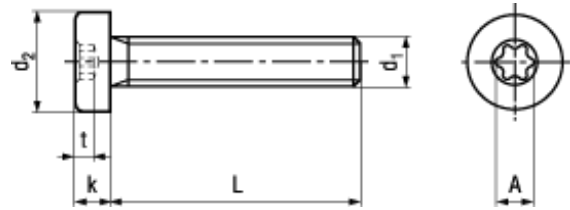

**BN 4850**


**Hexalobular (6 Lobe) socket head cap screws**


with low head, fully threaded

Steel 08.8 / 8.8

zinc plated blue

**i** Fasteners to the given specification have a reduced loadability due to the head geometry according to ISO 898-1.

Article#	d <sub>1</sub>	d <sub>2</sub> max.	k max.		t max.	A~	L
3645891	M3	5,5	2,4	X10	1,27	2,8	4
3271425							5
1145924							6
1145932							8
1145940							10
1145959							12
1145967							16
3055575							20
3271426							25
3271428							30
3645893							40
3645892							45
3645894	M4	7	3,1	X20	1,66	3,95	5
1145975							6
1145983							8
1145991							10
1146009							12
1146017							16
1146025							20
3055576							25
3271429							30
3645895							35
3645896							40
3645897							45
3645898							50
1146033	M5	8,5	3,65	X25	1,91	4,5	8

Article#	d <sub>1</sub>	d <sub>2</sub> max.	k max.		t max.	A~	L
1146041	M5	8,5	3,65	X25	1,91	4,5	10
1146068							12
1146076							16
1146084							20
1146092							25
3055577							30
3645899							35
3645900							40
3645901							45
3645902							50
3645903	M6	10	4,4	X30	2,29	5,6	6
1146106							8
1146114							10
1146122							12
1146130							16
1146149							20
1146157							25
1146165							30
3271430							35
3055578							40
3645904							45
3645905							50
1146173	M8	13	5,8	X45	3,05	7,95	10
1146181							12
1146203							16
1146211							20
1146238							25
1146246							30
3271431							35
1146254							40
3055579							50