


ISO 14583

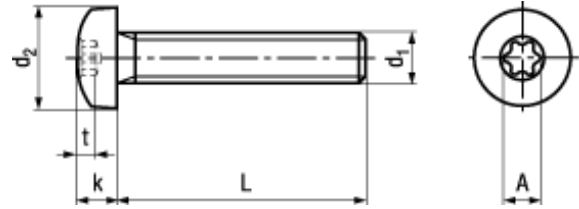


BN 5687


Hexalobular (6 Lobe) socket pan head machine screws


fully threaded

Stainless steel A2

- Tensile strength min. 600 N/mm²
- Proof stress 0,2% min. 450 N/mm²

Article#	d ₁	d ₂ max.	k max.		t max.	A~	L
3061578	M2	4	1,6	X6	0,77	1,75	3
3061579							4
3061581							5
3061582							6
3061583							8
3061584							10
3271646							12
3271647							16
3271648							20
3061585	M2,5	5	2,1	X8	1,04	2,4	3
3061587							4
3061588							5
3061597							6
3061598							8
3061600							10
3061601							12
3061603							16
3271651							20
3271652							25
3271654	M3	5,6	2,4	X10	1,27	2,8	4
3061604							5
3061605							6
3061606							8
3061608							10
3061609							12
3061610							16

Article#	d ₁	d ₂ max.	k max.		t max.	A~	L
3061611	M3	5,6	2,4	X10	1,27	2,8	20
3061612							25
3061613							30
3271655							35
3271657							40
3061615	M4	8	3,1	X20	1,66	3,95	6
3061616							8
3061619							10
3061620							12
3061621							16
3061622							20
3061623							25
3061624							30
3271658							35
3271659							40
3271660							45
3271662							50
3271664	M5	9,5	3,7	X25	1,91	4,5	6
3061626							8
3061627							10
3061628							12
3061629							16
3061944							20
3061945							25
3061946							30
3061947							35
3061949							40
3271665							45
3271666							50
3271667							60
3061951	M6	12	4,6	X30	2,42	5,6	8
3061952							10
3061953							12
3061955							16
3061956							20
3061957							25
3061958							30
3061959							35
3061961							40
3271668							45
3061965							50

Article#	d ₁	d ₂ max.	k max.		t max.	A~	L
3271669	M6	12	4,6	X30	2,42	5,6	60
3271670	M8	16	6	X45	3,18	7,95	10
3271671							12
3271672							16
3271673							20
3271674							25
3271675							30
3271676							35
3271677							40
3271678							45
3271679							50
3271680							60