


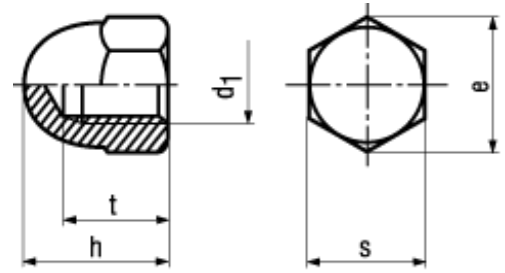

DIN 1587

**BN 635****Domed hex cap nuts**

(Acorn nuts)

Stainless steel A2

- ~UNI 5721



Material A2 or A1 at manufacturer's option

M3: not included in DIN 1587, M10; M12, M14: wrench size acc. ISO on request

Article#	d ₁	e min.	h	s	t min.	t max.
1413848	M3	6,01	6	5,5	3,6	4
1129341	M4	7,66	8	7	5,26	5,74
1242253	M5	8,79	10	8	7,21	7,79
1242261	M6	11,05	12	10	7,71	8,29
1242288	M8	14,38	15	13	10,65	11,35
1242296	M10	18,9	18	17	12,65	13,35
1242318	M12	21,1	22	19	15,65	16,35
1413856	(M14)	24,49	25	22	17,65	18,35
1076434	M16	26,75	28	24	20,58	21,42
1076442	M20	33,53	34	30	24,58	25,42
5800350	M24	39,98	42	36	30,5	31,5