




LED FIL T25X85 E14 4W (39W) 450lm 827 Clear Cooker Hood

Article number 80100038649

BAI LED Filament Tube T25 E144W 2700K Clear 450lm (39W) Cooker Hood 230V-240V 320° 25x85mm LED-lamp

LED filament lamps can be seen as the modern sustainable version of the old incandescent lamp. LED retrofit lamp to replace the conventional lamps in the extractor hood and to optimally illuminate the cooking environment.

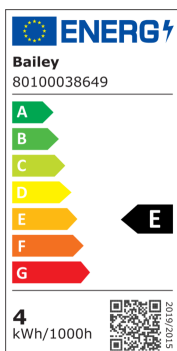

General ETIM properties

ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	80100038649
Brand	Bailey
Productseries	LED Filament tube
Product type	T25x85 Cooker Hood

ETIM specifications

IFTTT support available	No
Compatible with Amazon Alexa	No
Compatible with Google Assistant	No
Compatible with Apple HomeKit	No
Photobiological safety according to EN 62471	RG0
With remote control	No
Remote operation possible	No
Average nominal lifespan [h]	15000
Weighted energy consumption in 1000 hours [kWh]	4
Min. number of switching cycles	15000
Energy efficiency class	E
Lamp designation	Other
Energy Efficiency Index (EEI)	0.1
Degree of protection (IP)	IP20
Length [mm]	85
Diameter [mm]	25
Dimmable	No
Colour consistency (McAdam ellipse)	SDCM6
Beam angle [°]	320 - 320
Colour housing	Colourless
Colour temperature [K]	2700 - 2700
Colour	White
Socket	E14
Colour of light according to EN 12464-1	Warm white <3300 K
Type of glass/cover	Clear
Filament lamp	Yes
Lamp shape	Tube, single-ended
Colour rendering index CRI	80-89
Lamp efficacy [lm/W]	113
Luminous flux [lm]	450 - 450
Voltage type	AC
Lamp power [W]	4 - 4
Power factor	0.9
Nominal current [mA]	35 - 35
Nominal voltage [V]	220 - 240

Alternative articles



143286

LED FIL T25X85 E14
DIM 4W (35W) 400lm
827 Clear

80100839870