


LED FIL WarmDim C35 E14 3.5W (26W) 270-80lm 927-919 CL

Article number 80100040291

BAI LED Filament WarmDim Candle C35 E14 3.5W 2700-1900K Clear 270lm (26W) 230V-240V 280D 35x100mm B35 Dim to Warm Tone Glow Changing White

With Bailey's Dim to Warm LED filament lamp you can go from cozy warm light (2200K) to functional warm white light (3000K) and back again in literally an instant. The elegant LED filaments also give this light source a similar appearance to that of the incandescent lamp wires. Ideal for example above (dining) tables or in standing lamps to create a living room atmosphere. Consult the dimmer list to choose the correct dimmer.

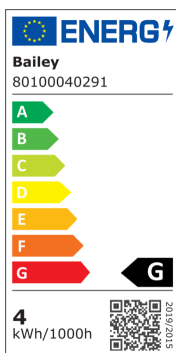

General ETIM properties

ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	80100040291
Brand	Bailey
Productseries	LED Filament WarmDim
Product type	DTW CL

ETIM specifications

IFTTT support available	No
Compatible with Amazon Alexa	No
Compatible with Google Assistant	No
Compatible with Apple HomeKit	No
Photobiological safety according to EN 62471	Other
With remote control	No
Remote operation possible	No
Average nominal lifespan [h]	15000
Weighted energy consumption in 1000 hours [kWh]	4
Min. number of switching cycles	100000
Energy efficiency class	G
Lamp designation	Other
Energy Efficiency Index (EEI)	0.15
Degree of protection (IP)	IP20
Length [mm]	100
Diameter [mm]	35
Dimmable	Yes
Colour consistency (McAdam ellipse)	SDCM5
Beam angle [°]	280 - 280
Colour housing	Colourless
Colour temperature [K]	1900 - 2700
Colour	White
Socket	E14
Colour of light according to EN 12464-1	Warm white <3300 K
Type of glass/cover	Clear
Filament lamp	Yes
Lamp shape	Candle
Colour rendering index CRI	90-100
Lamp efficacy [lm/W]	77
Luminous flux [lm]	270 - 270
Voltage type	AC
Lamp power [W]	3.5 - 3.5
Power factor	0.9
Nominal current [mA]	20 - 20
Nominal voltage [V]	220 - 240

Alternative articles



145007

SPIRALED Estelle C35
E14 DIM 2.2W 150lm
922 Clear

145468

SPIRALED WarmDim
C35 E14 3.3W (21W)
200lm 927-920 Clear

80100036364

LED FIL Wave C35
E14 DIM 3W (21W)
200lm 922