


**LED Ecobasic Compact T37 E27 7W (50W) 640lm 840**

Article number 80100040593

BAI Ecobasic LED Stick T37x116mm E27 7W 4000K 640lm (50W) Frosted 230V-240V 220° LED Compact lamp

Because these low-budget lamps are very durable due to their low consumption and long lifespan, they are both ECOlogical and ECONomic.

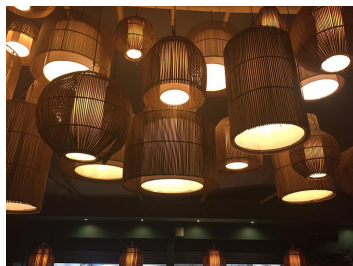

**General ETIM properties**

ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	80100040593
Brand	Bailey
Productseries	Ecobasic LED stick
Product type	Compact

### ETIM specifications

IFTTT support available	No
Compatible with Amazon Alexa	No
Compatible with Google Assistant	No
Compatible with Apple HomeKit	No
Photobiological safety according to EN 62471	Other
With remote control	No
Remote operation possible	No
Average nominal lifespan [h]	15000
Weighted energy consumption in 1000 hours [kWh]	7
Min. number of switching cycles	15000
Energy efficiency class	F
Lamp designation	Other
Energy Efficiency Index (EEI)	0.13
Degree of protection (IP)	IP20
Length [mm]	116
Diameter [mm]	37
Dimmable	No
Colour consistency (McAdam ellipse)	Other
Beam angle [°]	220 - 220
Colour housing	White
Colour temperature [K]	4000 - 4000
Colour	White
Socket	E27
Colour of light according to EN 12464-1	Neutral white 3300-5300 K
Type of glass/cover	Frosted
Filament lamp	No
Lamp shape	Tube, single-ended
Colour rendering index CRI	80-89
Lamp efficacy [lm/W]	91
Luminous flux [lm]	640 - 640
Voltage type	AC
Lamp power [W]	7 - 7
Power factor	0.5
Nominal current [mA]	58 - 58
Nominal voltage [V]	220 - 240

**Successor**



143615

EcoPack 3pcs LED  
T37 E27 9W (61W)  
820lm 840