 



BenQ BL2785TC

68,58 cm / 27" LED-Display

- FHD IPS Panel
- Height Adjustment incl. Pivot
- Noise-Cancelling Microphone
- USB-C Power Delivery

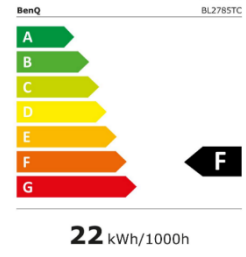

	Model : BL2785TC
	Art. Nr. / EAN Code : 9H.LKPLB.QBE/ 471 8755 08686 1
Panel	Type : 68,58 cm / 27" Wide, IPS-Panel
	Resolution: 1920 x 1080 Full-HD / 16:9
	Pixel Pitch : 0,311 mm
	Picture diagonal / -area (w x h) : 685,8 mm / 597,60 x 336,20 mm
	Max. Colors : 16,7 Mio.
	Panel : 8 Bit
	Viewing Angle H/V (CR>10) : 178° / 178°
	Contrast (static) : 1000:1
	Contrast (dynamic) : 20 million.:1
	Brightness : 250 cd/m ²
	Response Time : 5 ms (GtG)
Connection	HDMI connector : 1x HDMI 1.4
	USB-C : 1x (Power Delivery 60W)
	DP connector : 1x
	Headphone Jack : 1x
	DP Out (MST) : 1x
	Frequency H / V : 30 ~ 83 kHz / 50 - 76 Hz
Extras	Special : Flicker Free, Low Blue Light Plus, Brightness Intelligence, Color Weakness
	Speaker : 2x 2 Watt
	Protection : Kensington Lock
	Mounting: VESA 100 mm x 100 mm
	Height Adjustment : 130 mm incl. Pivot
	Tilt : -5° / -20°
	Rotatability : 45° / 45°
Energy	Power Supply : internal
	Voltage for operation : 100V – 240V / 50Hz – 60Hz
	Power consumption (Base on Energy Star) : 110 W
	Power consumption (On Mode) : 110 W
	Power consumption (Off Mode) : <0.3 W
Certification	Safety : CE
	Ergonomics : TÜV Bauart, TCO 8.0
	Environment : Energy Star 8.0, EPEAT Bronze
Environment	Operation : + 5 ~ +40°C ; 20 ~ 90% air humidity
	Storage : -20 ~ +60°C ; 10 ~ 90% air humidity
Characteristics	Weight net : 7.8 kg
	Housing Color : Black
	Dimension with base / w/o base (H x W x D) : 685,8 mm / 597,60 x 336,20 mm
	Accessories : Power-, HDMI-USB-C cable, QSG, Safety Instruction, Warranty Card
	Warranty terms : 3 years on-site exchange

