

## Euromas Aluminium / Euromas F05

Enclosure, aluminium



A 104

Order no.: 01104000

\* = Available on request.

### Characteristics

Colour of enclosure group

Grey, similar to RAL 7001

Protection class

IP 66

Enclosure Material

G Al Si 12, PU foamed seal

For details see Technical Information

### Scope of delivery

Lid and base, lid screws made of V2A, earthing screw

### Note

On the A 198, because of the wall-mounting drill holes inside the sealed lip, expert sealing of the wall-mounting is necessary to achieve protection class IP 66.


G = design with transparent lid (PC)

### Dimensions

Dimensions

115 x 64 x 34.5 mm

### Product drawing

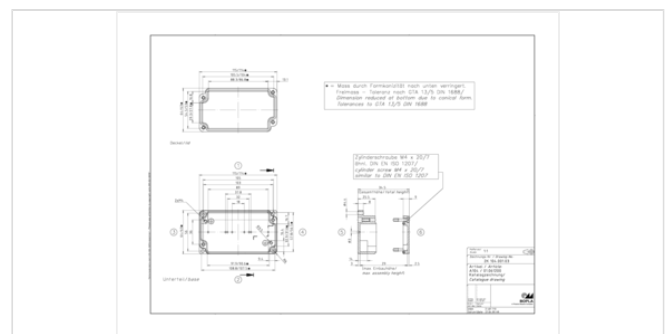

### Important!

To compensate for pressure when temperatures change and cause moisture in the enclosure, we recommend that you use a pressure compensation element.

» Additional information

20.02.2020

## Technical documentation / Downloads

---

### Technical drawings

3D product data in STEP format: Registration necessary  
Product drawing in PDF format: 01104000 A-104.pdf (71.9 KB)  
Product drawing in DXF format: 01104000 A-104.dxf (491.7 KB)  
Drawing for mechanical processing: 01104000 A-104-G.dxf (299.8 KB)

Milling contours are shown here as a DXF file. (Sub D, USB, HDMI, cable glands, ...)

### Works Test Certificates

682 WPZ-Euomas-Aluminium DE.pdf (163.7 KB)  
682 WPZ-Euomas-Aluminium EN.pdf (143.7 KB)

### Product information

Euomas Aluminium F05 GB.pdf (1.8 MB)

## Matching accessories

---



Capstan-headed screws, sealable

21007915 KP

For A 100-118



Allen cheese-head screw for lid

21007920 IS

For A 101-118



Set of hinges

21007800 SCHD