

# Euromas Aluminium / Euromas F05

Enclosure, aluminium



A 118

Order no.: 01118000

\* = Available on request.

## Characteristics

Colour of enclosure group

Grey, similar to RAL 7001

Protection class

IP 66

Enclosure Material

G Al Si 12, PU foamed seal

For details see Technical Information

## Scope of delivery

Lid and base, lid screws made of V2A, earthing screw

## Note

On the A 198, because of the wall-mounting drill holes inside the sealed lip, expert sealing of the wall-mounting is necessary to achieve protection class IP 66.


G = design with transparent lid (PC)

## Dimensions

Dimensions

160 x 100 x 81 mm

Product drawing

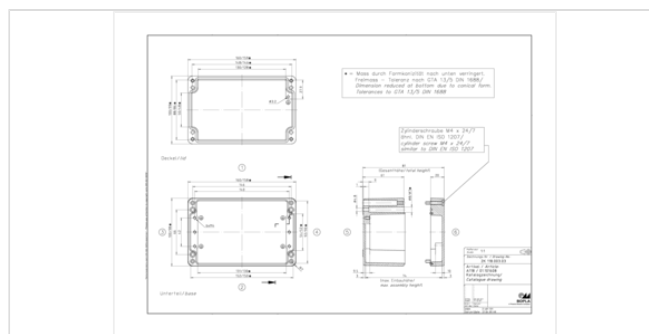

## Important!

To compensate for pressure when temperatures change and cause moisture in the enclosure, we recommend that you use a pressure compensation element.

» Additional information

20.02.2020

## Technical documentation / Downloads

---

### Technical drawings

3D product data in STEP format: Registration necessary  
Product drawing in PDF format: 01118000 A-118.pdf (72.3 KB)  
Product drawing in DXF format: 01118000 A-118.dxf (511.0 KB)  
Drawing for mechanical processing: 01118000 A-118-G.dxf (302.9 KB)

Milling contours are shown here as a DXF file. (Sub D, USB, HDMI, cable glands, ...)

### Works Test Certificates

682 WPZ-Euomas-Aluminium DE.pdf (163.7 KB)  
682 WPZ-Euomas-Aluminium EN.pdf (143.7 KB)

### Product information

Euomas Aluminium F05 GB.pdf (1.8 MB)

## Matching accessories

---



### Mounting panels, galvanised sheet steel

21001320 M For A 118



### Capstan-headed screws, sealable

21007915 KP For A 100-118



### Allen cheese-head screw for lid

21007920 IS For A 101-118



### DIN rails DIN EN 60715 G 32, galvanised steel

21003160 TS 32 For A 118



### Wall brackets, screw-on at rear

21004250 WL For A 114, A 116, A 118, P 305-322, P 324-329



### DIN rails DIN EN 60715 TH 15, galvanised steel

21003150 TS 15 For A 118, P 316



Set of hinges

21007800 SCHK

---