

Euromas Polyester

Enclosure, polyester



P 305

Order no.: 04305000

* = Available on request.

Characteristics

Colour of enclosure group
squirrel grey

Protection class
IP 66

Enclosure Material
UP-GF 25-30%, PU foamed seal; for details see Technical Information


Scope of delivery

Lid and base, lid screws made of V2A, earthing screw

Dimensions

Dimensions
80 x 75 x 56.5 mm

Product drawing

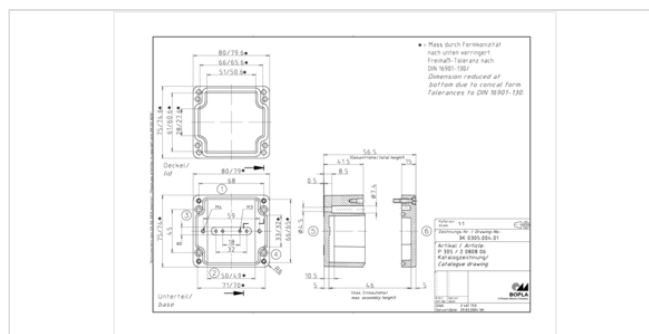

Important!

To compensate for pressure when temperatures change and cause moisture in the enclosure, we recommend that you use a pressure compensation element.

» Additional information

Technical documentation / Downloads

Technical drawings

3D product data in STEP format: Registration necessary
Product drawing in PDF format: 04305000 P-305.pdf (57.2 KB)
Product drawing in DXF format: 04305000 P-305.dxf (472.7 KB)
Drawing for mechanical processing: 04305000 P-305-G.dxf (647.7 KB)

Milling contours are shown here as a DXF file. (Sub D, USB, HDMI, cable)

20.02.2020

Product information

Euromas Polyester GB.pdf (308.6 KB)

glands, ...)

Works Test Certificates

683 WPZ-Euomas-Polyester DE.pdf (173.4 KB)

683 WPZ-Euomas-Polyester EN.pdf (152.0 KB)

Matching accessories



Mounting panels, laminated paper (P 305-329) or galvanised sheet steel (P 330-355)

24000100 M

For P 305



Capstan-headed screws, sealable

21007935 KP

For P 305-322, P 324-329



Allen cheese-head screw for lid

21007930 IS

For P 305-319, P 324-326, P 329



Wall brackets, screw-on at rear

21004250 WL

For A 114, A 116, A 118, P 305-322, P 324-329



DIN rails DIN EN 60715 TH 15, galvanised steel

21002800* TS 15

For A 105, P 305, P 326, PK 105



DIN rails DIN EN 60715 G 32, galvanised steel

22001701 TS 32

For M/T 210, M/T 225, P 305, P 326



DIN rails DIN EN 60715 TH 35, galvanised steel

22001702 TS 35

For M/T 210, M/T 225, P 305, P 326



Set of hinges

21007800 SCHED
