

Euromas Polyester

Enclosure, polyester



P 324

Order no.: 04324000

* = Available on request.

Characteristics

Colour of enclosure group
squirrel grey

Protection class
IP 66


Enclosure Material
UP-GF 25-30%, PU foamed seal; for details see Technical Information

Scope of delivery
Lid and base, lid screws made of V2A, earthing screw

Dimensions

Dimensions
110 x 75 x 75.5 mm

Product drawing

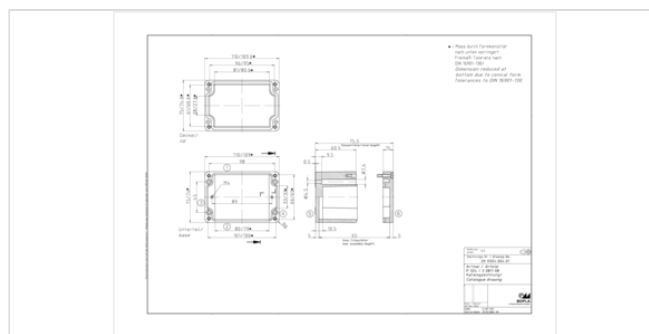

Important!

To compensate for pressure when temperatures change and cause moisture in the enclosure, we recommend that you use a pressure compensation element.

» Additional information

Technical documentation / Downloads

Technical drawings

3D product data in STEP format: Registration necessary
Product drawing in PDF format: 04324000 P-324.pdf (63.5 KB)
Product drawing in DXF format: 04324000 P-324.dxf (467.4 KB)
Drawing for mechanical processing: 04324000 P-324-G.dxf (642.8 KB)

Milling contours are shown here as a DXF file. (Sub D, USB, HDMI, cable

20.02.2020

Product information

Euromas Polyester GB.pdf (308.6 KB)

glands, ...)

Works Test Certificates

683 WPZ-Euomas-Polyester DE.pdf (173.4 KB)

683 WPZ-Euomas-Polyester EN.pdf (152.0 KB)

Matching accessories



Mounting panels, laminated paper (P 305-329) or galvanised sheet steel (P 330-355)

24000200 M

For P 311, P 324



Capstan-headed screws, sealable

21007935 KP

For P 305-322, P 324-329



Allen cheese-head screw for lid

21007930 IS

For P 305-319, P 324-326, P 329



Wall brackets, screw-on at rear

21004250 WL

For A 114, A 116, A 118, P 305-322, P 324-329



DIN rails DIN EN 60715 TH 15, galvanised steel

24003100 TS 15

For P 311, P 324



Set of hinges

21007800 SCHK