

# Ultramas

Enclosure with air vents in the lid and base



UM 32609 L

Order no.: 55326010

\* = Available on request.

## Characteristics

Colour of enclosure group  
Light grey, similar to RAL 7035

Protection class  
IP 30

Enclosure Material  
ABS; for details see Technical Information

## Scope of delivery

2 half-shells, 8 covers, 4 rubber feet, 4 screws


## Dimensions

Dimensions  
157.5 x 258.9 x 62.2 mm

U  
3

HP  
9

## Product drawing

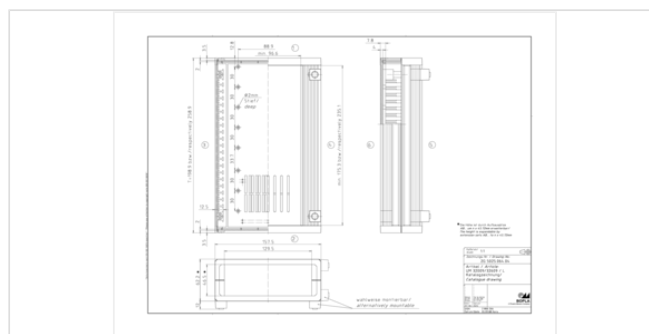

## Important!

To compensate for pressure when temperatures change and cause moisture in the enclosure, we recommend that you use a pressure compensation element.

» Additional information

## Technical documentation / Downloads

## Technical drawings

3D product data in STEP format: Registration necessary  
Product drawing in PDF format: 55326010 UM-32609-L.pdf (60.3 KB)  
Product drawing in DXF format: 55326010 UM-32609-L.dxf (618.1 KB)  
Drawing for mechanical processing: 55326010 UM-32609-L-G.dxf (1.1 MB)

Milling contours are shown here as a DXF file. (Sub D, USB, HDMI, cable glands, ...)

## Product information

Ultramas GB.pdf (368.7 KB)

## Matching accessories

---



### Extension set, plain, with air vents (L), 3 HP / 9 HP

56026500	AB 02603	3 HP; For UM 32609(L), 62609(L)
56026010	AB 02609 L	9 HP; For UM 32609(L), 62609(L)
56026000	AB 02609	9 HP; For UM 32609(L), 62609(L)



### Front panels, 2 mm, natural-coloured anodised aluminium

56033600	FP 30036	For UM 3..09 +3x AB 02.09 (L)
56033000*	FP 30030	For UM 3..09 + 1x AB 02.03 + 2x AB 02.09 (L)
56032700	FP 30027	For UM 3..09 + 2x AB 02.09 (L)
56032100	FP 30021	For UM 3..09 + 1x AB 02.03 + 1x AB 02.09 (L)
56031200	FP 30012	For UM 3..09 + 1x AB 02.03
56030900	FP 30009	For UM 3..09



### Front panels, ABS, light grey, similar to RAL 7035, embossed on one side

56031210	FPK 30012	For UM 3..09 + 1x AB 02.03
56033610	FPK 30036	For UM 3..09 +3x AB 02.09 (L)
56033010*	FPK 30030	For UM 3..09 + 1x AB 02.03 + 2x AB 02.09 (L)
56032710	FPK 30027	For UM 3..09 + 2x AB 02.09 (L)
56032110	FPK 30021	For UM 3..09 + 1x AB 02.03 + 1x AB 02.09 (L)
56030910	FPK 30009	For UM 3..09



### Tip-up foot set

56012000	UM-AS
----------	-------



### Tip-up foot set, collapsible

56012100	UM-ASK	Agate grey
----------	--------	------------



### Connection brackets

56002200*	UM-VHH	Agate grey
-----------	--------	------------



Rear panels, 2 mm, natural-coloured anodised aluminium

56031800 FPK 30018

For UM 3..09 + 1x AB 02.09 (L) and for  
UMP 32018 (FP)



Rear panels, light grey, 2 mm, plastic

56031810 FPK 30018

For UM 3..09 + 1x AB 02.09 (L) and for  
UMP 32018 (FP)



Wall brackets for UMP 32018 / 62018

56002000 UM-WLH

Agate grey



Screws (SHR) and distance bolts (DIBLZ) for mounting bosses in plastic enclosures

59006190 SHR Z KA25x6

SD = 2.5 / ND = 2.0 / KD = 4.4