


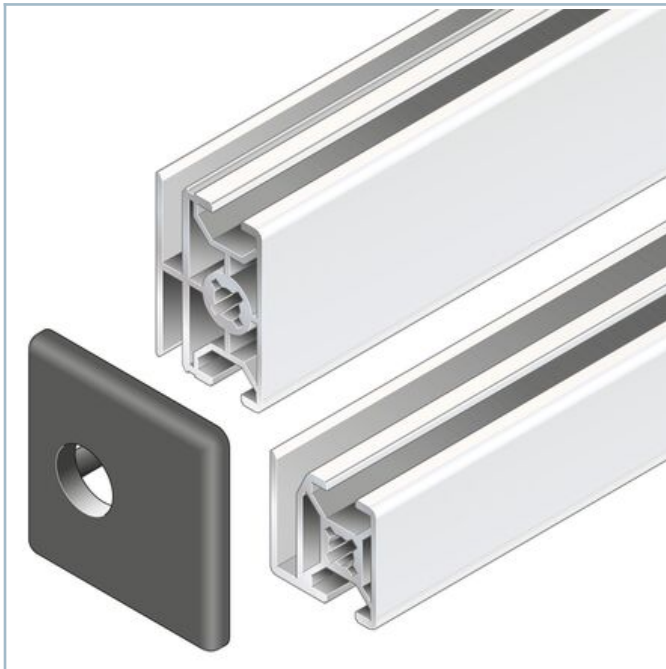


Protective grille profile WG30




- for the low-cost construction of protective barriers with woven wire grilles WG30 and WG40
- Fastening of woven wire grilles: directly in the special profile slot
- Fastening of surface elements: in the special profile slot using spring clamping elements (accessories)
- The profiles are connected using a central bolt (profile machining required)
- Modular dimension 'B' relates to 45x45 supports

- Cover cap 30x30
- Cover cap for a more attractive appearance and to prevent injuries

Product description

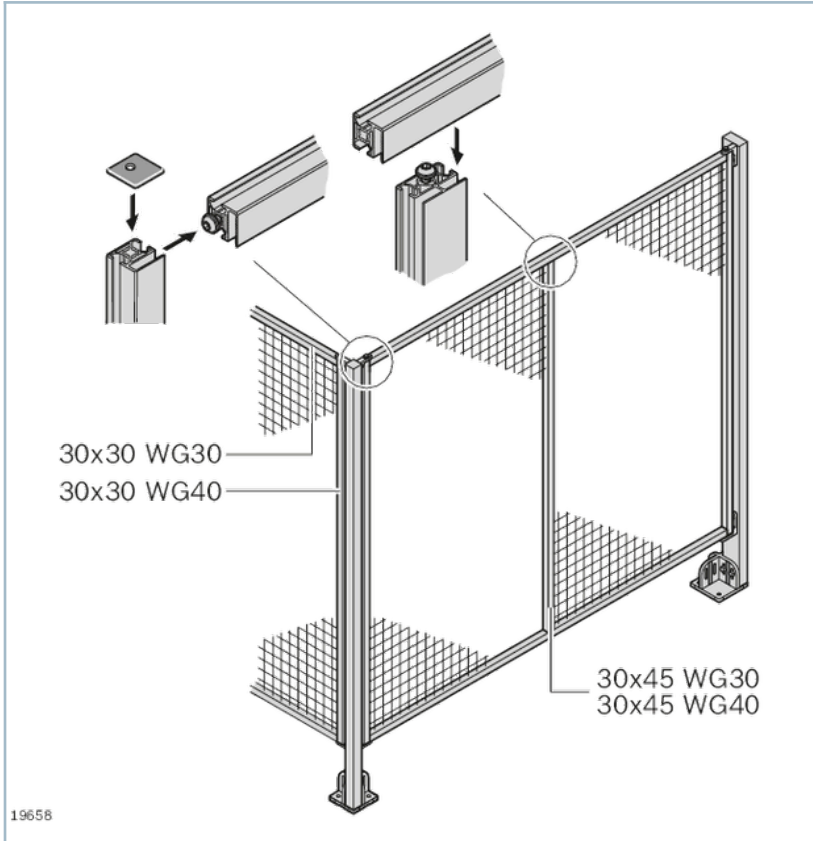


Technical data

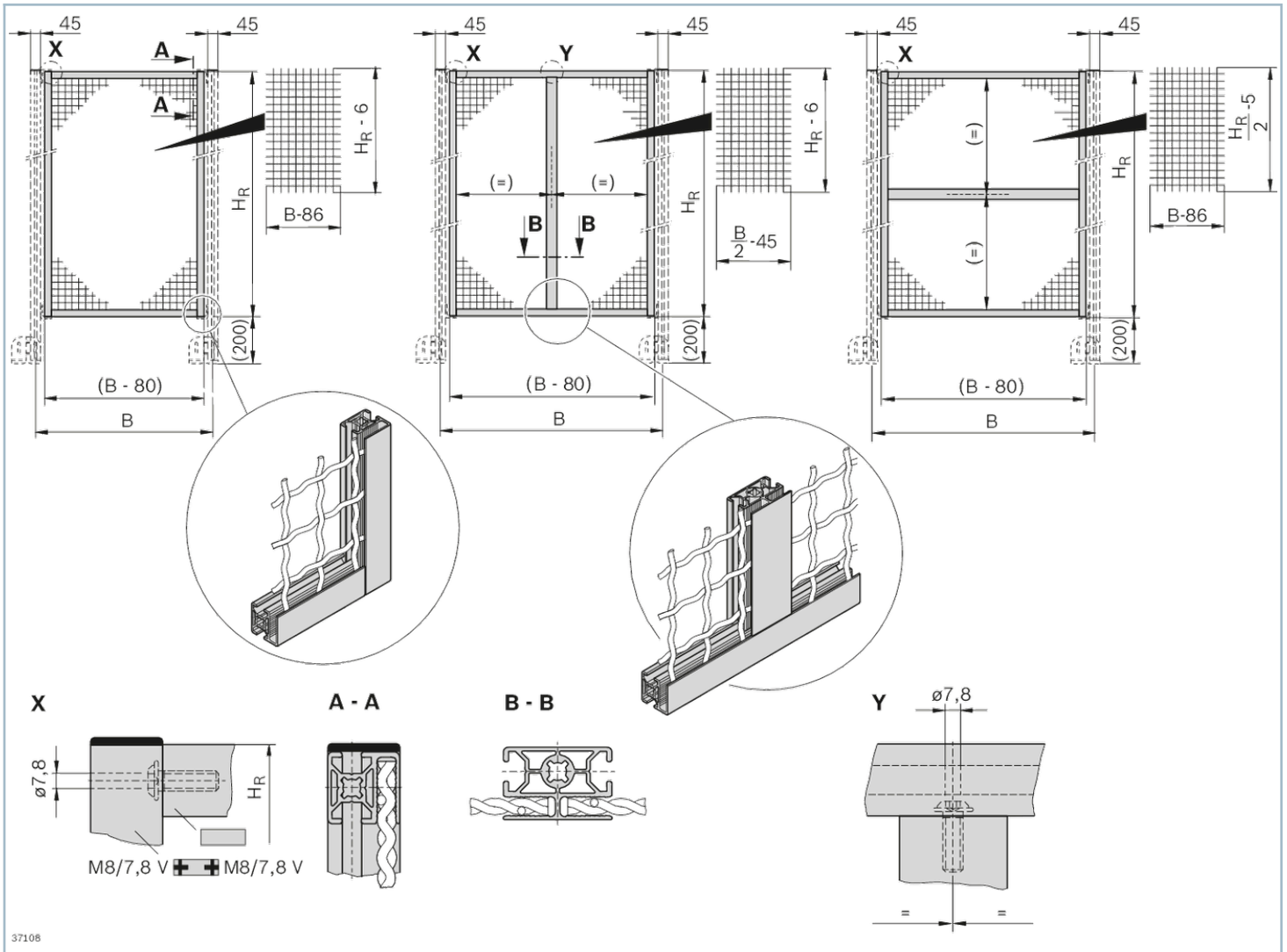

Dimensions

Protective grille profile 30x30 WG30

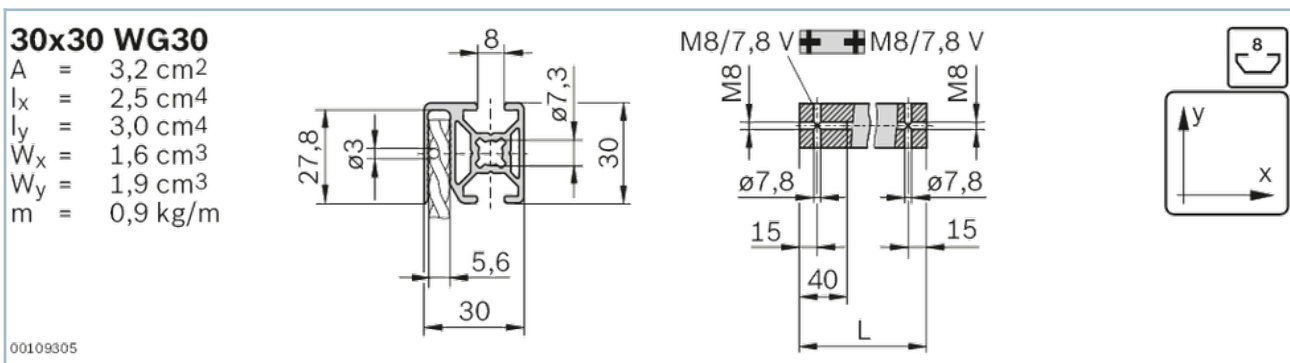


30x30 WG30


$A = 3,2 \text{ cm}^2$
 $I_x = 2,5 \text{ cm}^4$
 $I_y = 3,0 \text{ cm}^4$
 $W_x = 1,6 \text{ cm}^3$
 $W_y = 1,9 \text{ cm}^3$
 $m = 0,9 \text{ kg/m}$

00109305

Protective grille profile 30x45 WG30

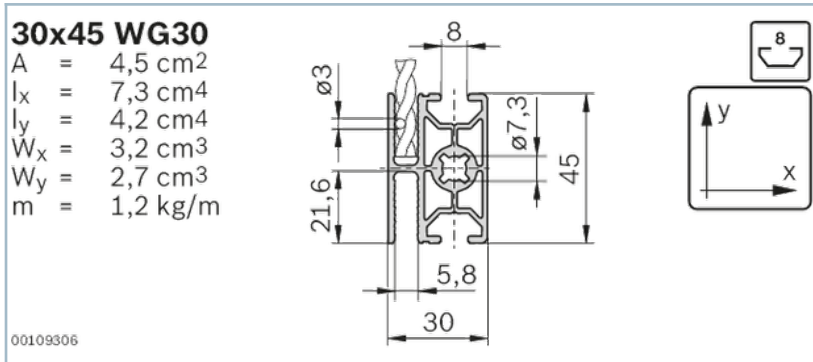

Cover cap 30x30 for protective grille profile

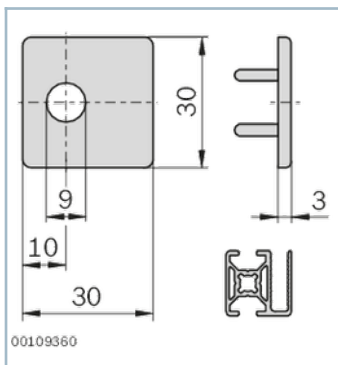


Accessories




Central bolt, cover cap

- Lowest-cost connecting element
- Self-tapping screw, can be mounted without profile finishing
- Profile finishing: Thread cutting for M12x30 screw, through-hole for screwdriver/offset screwdriver
- Cover cap for sealing through-holes in closed profiles

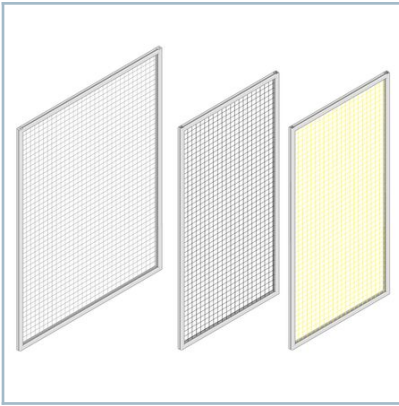

EcoSafe protective frame

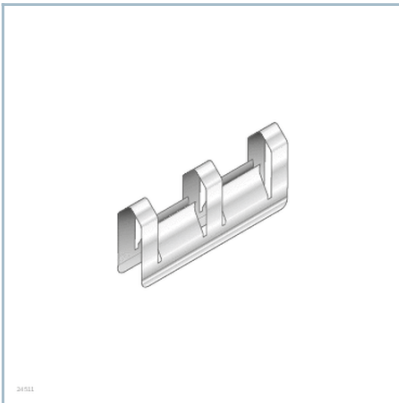

- Protective frame made of protective grille profile 30x30 WG40 with woven wire grille 40x40x4
- Suitable kits enable the construction of doors (system doors, sliding doors, double doors)
- Fully assembled on delivery
- Simple mounting on the supports using the suspension brackets. Single fitter is sufficient
- Standard widths or customized dimensions





Spring clamping element

- For clamping surface elements in EcoSafe protective fence profiles 30x30 WG30 and 30x30 WG40
- Play-free clamping
- Individual sections of the protective frames can be filled as you wish

Ordering codes

	L			No.
	mm			
Protective grille profile 30x30 WG30, individual profile finishes	100 ... 6070	1		3842992970
Protective grille profile 30x30 WG30, M8 D7,8V/M8 D7,8V standard profile finishes	100 ... 6000	1		3842992977
Protective grille profile 30x30 WG30, standard profile finishes	6070	20		3842557227
Protective grille profile 30x45 WG30, L100-5600	100 ... 6070	1		3842992971

	L			No.
	mm			
Protective grille profile 30x45 WG30, L5600	6070	20		3842557228
Cover cap, protective grille profile 30x30, black			100	3842522345
Cover cap, protective grille profile 30x30, signal gray			20	3842555134
			100	3842555135
Protective grille profile 30x30 WG30, standard profile finishes	6170	1		3842557237
Protective grille profile 30x45 WG30	6170	1		3842557238