


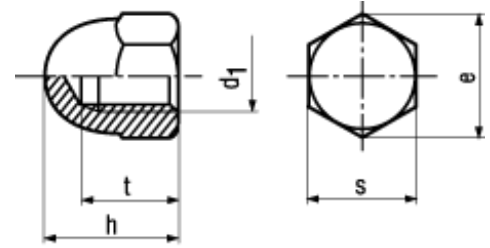

DIN 1587

6

**BN 150****Hex domed cap nuts**

(Acorn nuts)

Steel 6

zinc plated blue

- ~UNI 5721

M3: not included in DIN 1587, M10; M12; M14; M22: wrench size according to ISO on request

Article#	d ₁	e min.	h	s	t min.	t max.
1092898	M3	6,08	6	5,5	3,6	4
1092901	M4	7,66	8	7	5,26	5,74
1092928	M5	8,79	10	8	7,21	7,79
1092936	M6	11,05	12	10	7,71	8,29
1092944	M8	14,38	15	13	10,65	11,35
1092952	M10	18,9	18	17	12,65	13,35
1092960	M12	21,1	22	19	15,65	16,35
1092979	(M14)	24,49	25	22	17,65	18,35
1092987	M16	26,75	28	24	20,58	21,42
1092995	(M18)	30,14	32	27	24,58	25,42
1093002	M20	33,53	34	30	25,58	26,42
1093010	(M22)	35,72	39	32	28,58	29,42
1093029	M24	39,98	42	36	30,5	31,5