


Alligator®



Conventional water pump pliers

Alligator® 250/300

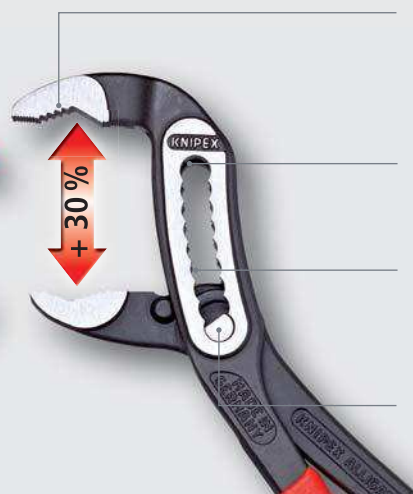

pecially hardened teeth
high resistance to wear, allowing durable, reliable gripping

robust adjusting mechanism
insensitive to dirt, particularly suitable for outdoor work

notch curved adjustment positioning
30% more gripping capacity, optimised adjustment to the workpiece and a handy handle position, slim design

box joint, double guide
no loosening of the joint connection, continuous heavy duty

Article No.	EAN 4003773-	↔ mm		Pliers	Head	Handles	∅ Inch	∅ mm	mm	Adjustment positions	g	
88 01 180	035480	180		black	polished	plastic coated	1 1/2	42	36	9	180	
88 01 250	022992	250		atramentized			2	50	46	9	319	
88 01 300	034094	300					2 3/4	70	60	9	511	
88 02 180	044222	180		black	polished	with multi-component grips	1 1/2	42	36	9	215	
88 02 250	019282	250				with slim multi-component grips	2	50	46	9	357	
88 02 250 T	080176	250				atramentized	with slim multi-component grips and integrated tether attachment point	2	50	46	9	361
88 02 300	029151	300					with multi-component grips	2 3/4	70	60	9	565
88 02 300 T	080619	300					with multi-component grips and integrated tether attachment point	2 3/4	70	60	9	569
88 03 180	042860	180				chrome plated		plastic coated	1 1/2	42	36	9
88 03 250	005742	250				2	50	46	9	317		
88 05 180	060130	180		chrome plated		with multi-component grips	1 1/2	42	36	9	214	
88 05 250	035497	250						2	50	46	9	344
88 05 300	042389	300						2 3/4	70	60	9	560
88 06 250	039303	250	 	chrome plated		insulated with multi-component grips, VDE-tested	2	50	46	9	374	
88 07 250	019343	250	 	chrome plated		with dipped insulation, VDE-tested	2	50	46	9	420	
88 07 300	022350	300					2 3/4	70	60	9	661	

* Other tools with tethering can be found from page 254 ff